


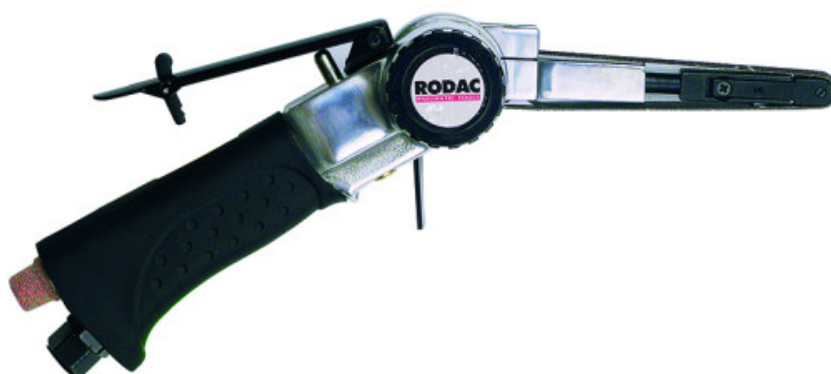

BAND SANDER 20MM

RC8440A

SAM Outillage

10 rue Camille de RochetaillÃ©e
42000 Saint-Etienne - France

RCS Saint-Etienne B 338 002 231 | SAS au capital de 8 189 583 â‚¬

<https://www.sam-outillage.com/>

Photos and texts not contractually binding. Do not litter. Document generated on 2025-07-18 15:13:11





DESCRIPTION

BAND SANDER 20MM

PRACTICAL Capable of multi-position working, it is ideal for removing weld spots. Sander for applications on large surfaces. Will be very useful for difficult-to-access and small surfaces. You can use it inside handles, corner brackets and tubes, as well as on edges. Ergonomic model with directable sheathed handle. Safety trigger and exhaust silencer. Variable speed control and adjustable arm. Tension mechanism for fast belt changing.

SPECIFIC DATA

Designation	BAND SANDER 20MM
Sales reference	RC8440A
Weight (g)	1800

SAM Outillage

10 rue Camille de RochetaillÃ©e
42000 Saint-Etienne - France

RCS Saint-Etienne B 338 002 231 | SAS au capital de 8 189 583 Å,-

<https://www.sam-outillage.com/>

Photos and texts not contractually binding. Do not litter. Document generated on 2025-07-18 15:13:11



l (mm)	115
h (mm)	75
Power (W)	450
Length (mm)	400
Rotation speed (rpm)	16 000
Vibration (m/s²)	0,8
Noise level (dBa)	83
C mm	6,3
C min mm	250
C mm	1/4
Band dimensions	20x520mm
Guarantee	M2 SAM Equipment and Machine Guarantee

Guarantee applied

M2 | SAM Equipment and Machine Guarantee

Guarantee for a limited period, covering technical tools, devices and machines used under normal conditions. The length is given by the number after the letter M: 1 to 5 years

[>> Find out more](#)

SAM Outillage

10 rue Camille de RochetaillÃ©e
42000 Saint-Etienne - France

RCS Saint-Etienne B 338 002 231 | SAS au capital de 8 189 583 â‚¬

<https://www.sam-outillage.com/>

Photos and texts not contractually binding. Do not litter. Document generated on 2025-07-18 15:13:11

