



Product Compliance


[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUL 2021 (219) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not reviewed for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Customers Also Bought

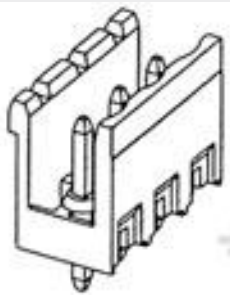


TE Part #282824-4
TERMI-BLOK HEADER, ASSY90 4P.5

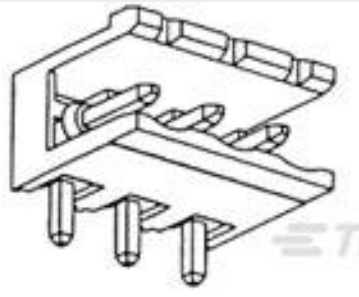

TE Part #282815-5
TERMI-BLOK HEADER, ASSY90 5P.5

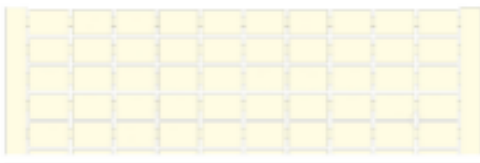

TE Part #1SNA230003R0100
RC55 11->20 (X10) HORIZONTAL

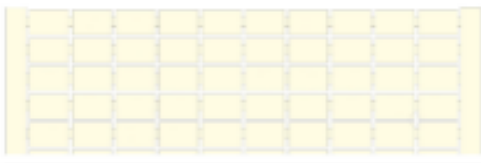


TE Part #1SNA230002R0000
RC55 1->10 (X10) HORIZONTAL



TE Part #102394-7
18 AMP MODU MT HSG DR .100CL



TE Part #7-2176414-4
7W STD M/OX 5% 22K

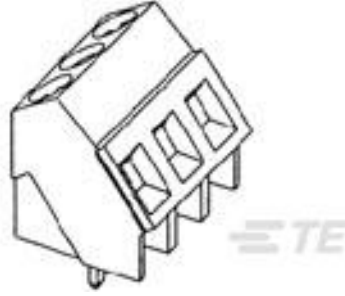

TE Part #796689-5
TERMI-BLOK PCB MOUNT 5P.



TE Part #3-284932-6
DUOPLUG MKI STD, 6 POS, KEYED 4



TE Part #4-1534796-6
AMP DUOPLUG MARK II
CONNECTOR 3-20POS



TE Part #1-1355181-6
DUOPLUG2, 5GEH 6P 8X

Documents

Product Drawings

AMP DUOPLUG MARK II CONNECTOR3-20P SELEC

English

CAD Files

Customer View Model

ENG_CVM_CVM_5-1534798-8_A.2d_dxf.zip

English

3D PDF

3D

Customer View Model

ENG_CVM_CVM_5-1534798-8_A.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_5-1534798-8_A.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages



[RAST Connector System Catalog](#)

English

[Product Specifications](#)

[Application Specification](#)

English

[Agency Approvals](#)

[VDE Certificate](#)

English

[VDE Certificate](#)

English

[VDE Certificate](#)

English