


BK-3MCDE CASE

eneloop AA (Standard) — Case Pack

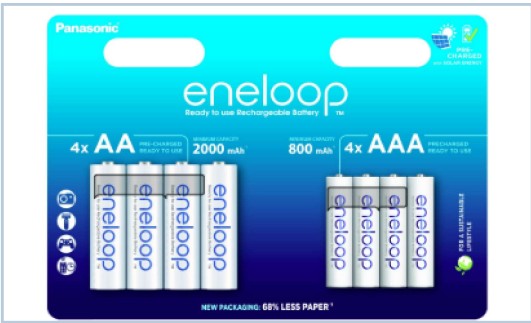

Key Specifications

Parameter	Value
Part Number	BK-3MCDE CASE
Cell size	AA (Mignon)
Chemistry	Ni-MH, LSD
Nominal voltage	1.2 V
Capacity (typ. / min.)	2000 mAh / 1900 mAh
Rechargeable cycles	Up to 2,100 times
Charge retention	70% after 10 years storage
Dimensions (H x Ø)	50.4 mm x 14.35 mm
Weight	≈27 g per cell
Operating temperature	0°C to 50°C
Pack type	Bulk/case carton — multiple retail 4-packs per case

Panasonic eneloop Technical Reference Sheet — compiled for reference use, not an official Panasonic publication.