

FEATURES

- T8 Twin LED batten
- 3 hours switch maintained emergency
- Rate of Protection: IP20
- 30000 lifetime hours
- Metal body with White finish
- Non-Dimmable
- Lamp Type SMD LED
- Material Polycarbonate and Pressed Steel

LED Emergency Lighting Batten 60 W

RS Stock No.: 125-6921



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

This RS PRO twin LED 3 hour switched maintained emergency batten is a great replacement for traditional T8 battens. Led lamp technology brings energy savings through lower power consumption and maintenance is reduced due to 30000 lifetime hours. Led lamp technology allows instant light at a colour temperature of cool white (4000K) with no warm-up time. This RS Pro LED batten is surface mounted and incorporates a polycarbonate diffuser to an IP20 rate of protection.

General Specifications

Lamp Type	LED
Light Style	Bulkhead
Luminosity	6500lm
Colour Temperature	4000K
Maintained	Maintained
Material	Steel + Polycarbonate
Finish	Cool White
Duration	3h
Lamp Supplied	Yes
Applications	Ideal for commercial, industrial and retail applications and can be found in: Corridors, Workshops, emergency exits, Carparks

Electrical Specifications

Wattage	60W
Voltage Rating	230VDC
Running Current	0.266A

Mechanical Specifications


Length	1790mm
Width	95mm
Depth	85mm
Fitting Type	Batten
Weight	3.38kg

Protection Category

IP Rating	IP20
-----------	------

Approvals

Compliance/Certifications	RoHS
EU Energy Efficiency Rating	A+

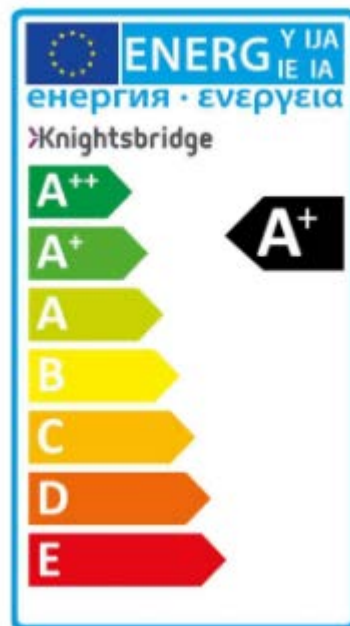

Ling Diagram:

