


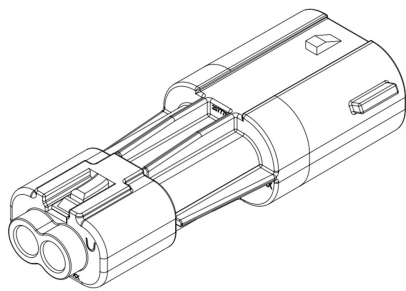

**Part Number :** [2077780213](#)  
**Product Description :** Squba 3.6 Sealed Plug Assembly, 3.60mm Pitch, 3 Circuits, Single Row, Glow-Wire Capable, Key B, Natural, UL1015/UL1230 Compatible  
**Series Number :** 207778  
**Status :** Active  
**Product Category :** Connector Housings



Documents & Resources

**Drawings**  
[2077780213\\_sd.pdf](#)  
[2077780000-PK-000.pdf](#)

**3D Models and Design Files**  
[2077780213\\_stp.zip](#)

**Specifications**  
[2077760000-AS-000.pdf](#)  
[2077760000-PS-000.pdf](#)  
[2077760000-TS-000.pdf](#)

Product Environment Compliance

Compliance

|                    |                                                |
|--------------------|------------------------------------------------|
| GADSL/IMDS         | Not Relevant                                   |
| China RoHS         |                                                |
| EU ELV             | Not Relevant                                   |
| Low-Halogen Status | Not Low-Halogen per IEC 61249-2-21             |
| REACH SVHC         | Not Contained per D(2024)6225-DC (07 Nov 2024) |
| EU RoHS            | Compliant per EU 2015/863                      |

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

## Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

## EU RoHS Certificate of Compliance

---

### Part Details

#### General

|              |                                                                                                                                   |
|--------------|-----------------------------------------------------------------------------------------------------------------------------------|
| Status       | Active                                                                                                                            |
| Category     | Connector Housings                                                                                                                |
| Series       | 207778                                                                                                                            |
| Description  | Squba 3.6 Sealed Plug Assembly, 3.60mm Pitch, 3 Circuits, Single Row, Glow-Wire Capable, Key B, Natural, UL1015/UL1230 Compatible |
| Application  | Power, Signal, Wire-to-Wire                                                                                                       |
| Product Name | Squba                                                                                                                             |
| UPC          | 196823171581                                                                                                                      |

#### Agency

|    |        |
|----|--------|
| UL | E29179 |
|----|--------|

#### Physical

|                       |         |
|-----------------------|---------|
| Circuits (maximum)    | 3       |
| Color - Resin         | Natural |
| Flammability          | 94V-0   |
| Gender                | Plug    |
| Glow-Wire Capable     | Yes     |
| Keying to Mating Part | None    |
| Lock to Mating Part   | Yes     |
| Material - Resin      | Nylon   |
| Net Weight            | 4.024/g |
| Number of Rows        | 1       |
| Packaging Type        | Bag     |

|                               |                |
|-------------------------------|----------------|
| Panel Mount                   | No             |
| Pitch - Mating Interface      | 3.60mm         |
| Pitch - Termination Interface | 3.60mm         |
| Polarized to Mating Part      | Yes            |
| Temperature Range - Operating | -40° to +105°C |

---

## Mates With / Use With

### Mates with Part(s)

| Description                                                                                                                             | Part Number       |
|-----------------------------------------------------------------------------------------------------------------------------------------|-------------------|
| Squba 3.6 Sealed Receptacle Assembly, 3.60mm Pitch, 3 Circuits, Single Row, Glow-Wire Capable, Key B, Natural, UL1015/UL1230 Compatible | <u>2077820213</u> |

### Use with Part(s)

| Description                                                                           | Part Number       |
|---------------------------------------------------------------------------------------|-------------------|
| Squba 3.6 Plug Terminal, Matte Tin Plating, UL1015/UL1230 Compatible, 20-18 AWG, Reel | <u>2077760003</u> |
| Squba Weather Cap for 6 or 3 Circuit Plug Housing                                     | <u>2204230006</u> |