

Features

- Non-Sparking
- Hammer types for Sledgehammer and Ball Pein Hammer
- Beryllium Copper Hammer Head
- Fiberglass Handle
- Weight range from 340g to 5kg
- Non-magnetic and highly corrosion resistant

RS PRO Beryllium Copper Hammer with Fiberglass Handle



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

RS PRO Beryllium Copper Hammer with Fiberglass Handle, Non-sparking

RS PRO series non sparking hammer uses ?? handle to prevent any risk of sparks and is made of copper beryllium alloy.

Benefit and Features

- *Precision Casting*
- *Most common striking tools. Used in metal working*
- *With Safety Pin*
- *Copper Beryllium material*
- *Non-Sparking and Non-magnetic*

General Specifications

Hammer Type	See details below
Head Type	See details below
Non-Sparking	Yes
Head Material	Beryllium Copper
Handle Material	Fiberglass
Overall Length	See details below
Weight	See details below

Stock No.	Hammer Type	Head Type	Weight	Overall Length
0441249	Ball-Pein Hammer	Ball Pein	340g	290 mm
0441250	Ball-Pein Hammer	Ball Pein	450g	310 mm
0441251	Ball-Pein Hammer	Ball Pein	680g	340 mm
0441253	Sledgehammer	Sledge	450g	310 mm
0441254	Sledgehammer	Sledge	1.0kg	370 mm
0441255	Sledgehammer	Sledge	1.4kg	400 mm
0441257	Sledgehammer	Sledge	2.0kg	400 mm
0441258	Sledgehammer	Sledge	3.0kg	700 mm
0441260	Sledgehammer	Sledge	5.0kg	900 mm


Approvals

Declarations	REACH DoC
Standards Met	QB/T 2613.7 (Ball-Pein Hammer) QB/T 2613.6 (Sledgehammer)

Similar Products


Stock No.	Brand	Product Name	Head Type	Weight	Overall Length
0441249	RS PRO	Ball Pein Hammer	Ball Pein	340g	290 mm
0441250	RS PRO	Ball Pein Hammer	Ball Pein	450g	310 mm
0441251	RS PRO	Ball Pein Hammer	Ball Pein	680g	340 mm
0441253	RS PRO	Sledgehammer	Sledge	450g	310 mm
0441254	RS PRO	Sledgehammer	Sledge	1.0kg	370 mm
0441255	RS PRO	Sledgehammer	Sledge	1.4kg	400 mm
0441257	RS PRO	Sledgehammer	Sledge	2.0kg	400 mm
0441258	RS PRO	Sledgehammer	Sledge	3.0kg	700 mm
0441260	RS PRO	Sledgehammer	Sledge	5.0kg	900 mm

Ball-Pein Hammer

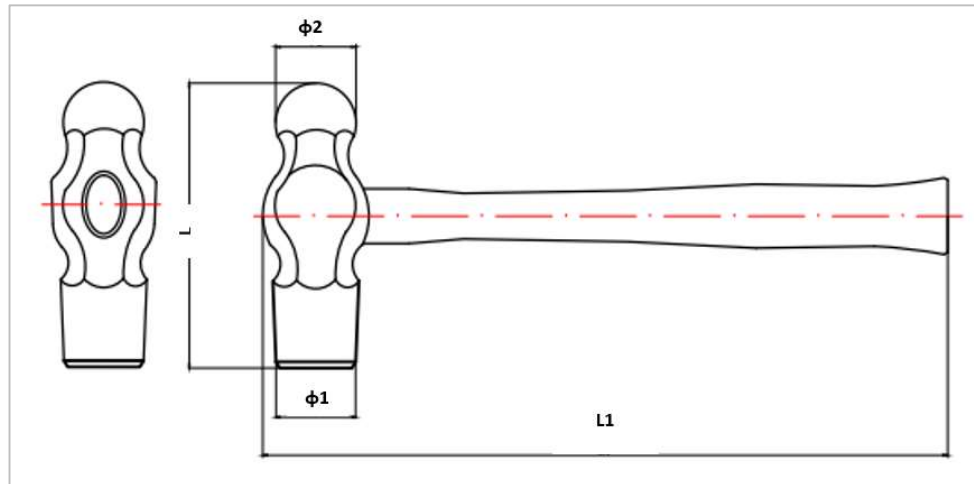

680	112	340	31	31	870
450	101	310	25	28	580
340	89	290	24	26	470
Weight (g)	$L \pm 2.5$	$L_1 \pm 8$	$\phi 1 \pm 2$	$\phi 2 \pm 2$	WGT (g)

Sledgehammer

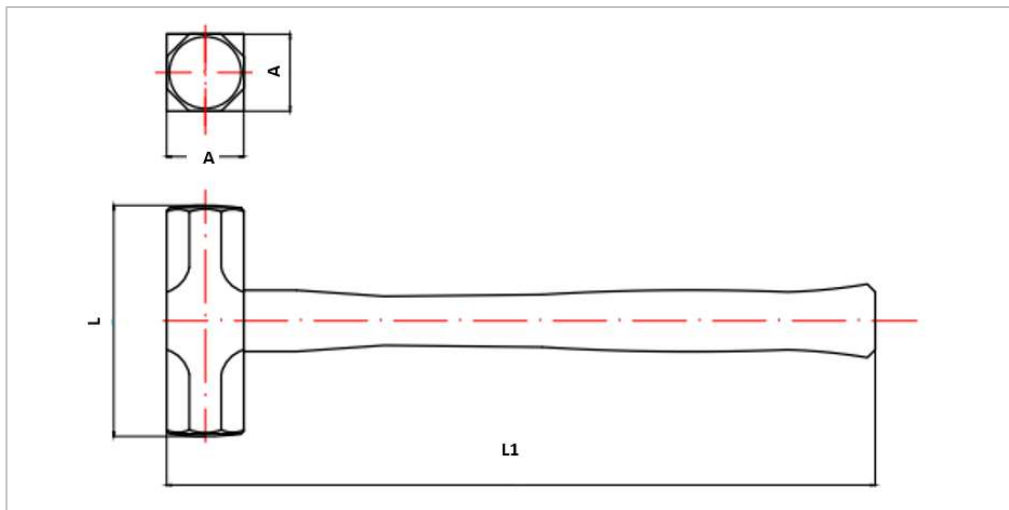

5000	180	900	65
3000	160	700	54
2000	132	400	48
1400	116	400	44
1000	100	370	40
450	86	310	29
Weight (g)	$L \pm 2.5$	$L_1 \pm 8$	$A \pm 2$