



Brand of NTN Group

Technical data

UCF214

Bearing units




Grey cast housing, radial insert ball bearing with socket set screws, seal with slinger

KIT CONTENT

UC214G2, F214

VISUAL (S)

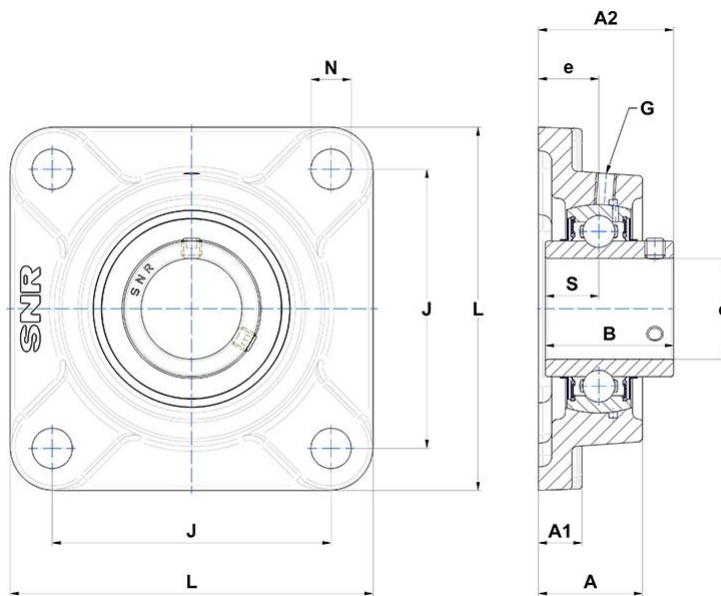

PRODUCT DEFINITION

Brand	SNR
A - Housing height	54 mm
A1 - Housing foot height / flange height	22 mm
A2 - Total height from mounting surface	75,4 mm
B - Width of Inner Ring	74,6 mm
d - Shaft diameter	70 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

e - Distance mounting surface to bearing center	31 mm
G - Grease fitting	M10x1
J - Mounting holes distance	152 mm
L - Housing width / diameter	193 mm
N - Mounting hole dimension	19 mm
S - Distance front side/bearing centre	30,2 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	62000000 mN
C0 - Static load rating	45000000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	6,21 kg
Recommended tightening torque for set screw	33 N-m

