


# Product Data Sheet

## MaxiChem® 56-635

<b>Colour – Coating</b>	Green/black
<b>Colour – Liner</b>	Neutral
<b>Design</b>	Gauntlet - 35 cm
<b>Coating</b>	NBR (Nitrile Butadiene Rubber)
<b>Coating texture</b>	Micro-Foam with Non-Slip Grip
<b>Liner</b>	Nylon
<b>Patent number</b>	EP 1 608 808
<b>Palm thickness</b>	1.30 mm

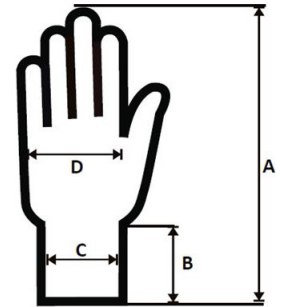

### Dimensions

Size Range	Size 7 (S)	Size 8 (M)	Size 9 (L)	Size 10 (XL)	Size 11 (XXL)
Total glove length (+/-10 mm)	350	350	350	350	350
Wrist length (mm)					
Wrist width (mm)					
Palm width (+/-3 mm)	104	109	111	116	120
Over lock colour	Red	Orange	White	Yellow	Black

### EN test Results

Test	Notified Body	Result/Pass
EN ISO 374-1: 2016/Type A	TÜV Rheinland	JKLMNO
EN ISO 374-5: 2016	TÜV Rheinland	Yes
EN ISO 21420: 2020	TÜV Rheinland	Yes
EN 388: 2016 + A1: 2018	TÜV Rheinland	4121A



# Product Data Sheet

## MaxiChem® 56-635

### Typical Performance Values

EN ISO 374-1:2016 J - n-Heptane	6 (>480 min)
EN ISO 374-1:2016 K - Sodium hydroxide 40%	6 (>480 min)
EN ISO 374-1:2016 L - Sulphuric acid 96%	4 (>120 min)
EN ISO 374-1:2016 M - Nitric acid 65%	4 (>120 min)
EN ISO 374-1:2016 N - Acetic acid 99%	3 (>60 min)
EN ISO 374-1:2016 O - Ammonia 25%	6 (>480 min)
EN ISO 374-1:2016 Protective gloves against dangerous chemical risks	The permeation performance shall be at least level 2 against a minimum of six test chemicals
EN ISO 374-5:2016 Protective gloves against microorganisms	Yes
EN ISO 21420 Dexterity	Level 5
EN 388:2016 + A1:2018 A. Abrasion Resistance	> 8000 Cycles
EN 388:2016 + A1:2018 B. Cut Resistance	> 1.2 index
EN 388:2016 + A1:2018 C. Tear Resistance	> 25 newtons
EN 388:2016 + A1:2018 D. Puncture Resistance	> 20 newtons
EN 388:2016 + A1:2018 E. Cut Resistance ISO	≥ 2 Newton

### HandCare®

Skin Health Alliance Dermatologically Accredited	Yes
REACH compliant	Yes
Standard 100 by OEKO-TEX® (08.BH.57867)	Certified
Sanitized®	Yes



# Product Data Sheet

## MaxiChem® 56-635

### Special features

Silicone free	Yes
---------------	-----

### Packaging

Pairs per poly bag	12
Poly bags per carton	6
Carton count	72
Carton dimensions (mm)	500 x 295 x 350

### Weight

Size Range	Size 7 (S)	Size 8 (M)	Size 9 (L)	Size 10 (XL)	Size 11 (XXL)
Glove weight / Pair (+/-6 gram)	116	126	132	136	144
Gross Weight (Kg)	9.5	10.2	10.7	11	11.5
Carton Weight (Kg)	1	1	1	1	1
Net Weight (Kg)	8.5	9.2	9.7	10	10.5

Issue date: 30.01.2019

