




**Part Number :** [797582147](#)

**Product Description :** Pre-Crimped Lead Mini-Lock Female-to-Mini-Lock Female, Tin (Sn) Plating, 150.00mm Length, 22 AWG, Black

**Series Number :** 79758

**Status :** Active

**Product Category :** Power and Signal Cable Assemblies

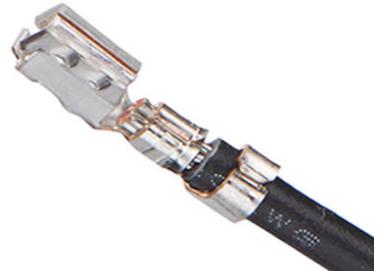

## Documents & Resources

### Drawings

[797582147\\_sd.pdf](#)

## Product Environment Compliance

### Compliance

|                    |  |
|--------------------|--|
| GADSL/IMDS         | Not Relevant                                   |
| China RoHS         | ⓘ<br>per SJ/T 11365-2006                       |
| EU ELV             | Not Relevant                                   |
| Low-Halogen Status | Not Low-Halogen per IEC 61249-2-21             |
| REACH SVHC         | Not Contained per D(2024)7663-DC (21 Jan 2025) |
| EU RoHS            | Compliant per EU 2015/863                      |

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

## Substances of Interest

- PFAS

## EU RoHS Certificate of Compliance

## Additional Product Compliance Information

---

## Part Details

### General

|                        |  |
|------------------------|--|
| Status                 | Active   |
| Category               | Power and Signal Cable Assemblies  |
| Series                 | 79758  |
| Description            | Pre-Crimped Lead Mini-Lock<br>Female-to-Mini-Lock Female, Tin<br>(Sn) Plating, 150.00mm Length, 22<br>AWG, Black |
| Assembly Configuration | Pre-crimped Lead Only  |
| Connector to Connector | Mini-Lock Crimp Terminals  |
| Keyword                | Pre-Crimped Leads  |
| Product Name           | Mini-Lock  |
| UPC                    | 193264197675   |

### Physical

|                                |                      |
|--------------------------------|----------------------|
| Cable Length                   | 150.00mm             |
| Circuits (Loaded)              | 1                    |
| Circuits (maximum)             | 1                    |
| Color - Resin                  | Black                |
| Gender                         | Female-Female        |
| Material - Metal               | Phosphor Bronze      |
| Material - Plating Mating      | Tin                  |
| Material - Plating Termination | Tin                  |
| Net Weight                     | 0.850/g              |
| Packaging Type                 | Bag                  |
| Single Ended                   | No                   |
| Termination Interface Style    | Crimp or Compression |
| Wire/Cable Type                | UL 1061              |
| Wire Size (AWG)                | 22                   |

## Mates With / Use With

### Use with Part(s)

| Description                              | Part Number  |
|--|--------------|
| Mini-Lock Single Row Receptacle Housings | <u>51103</u> |

---

This document was generated on Aug 05, 2025