

Features

- Crocodile Clips
- Automotive clip
- Jaw open: 1-1/16" (27 mm) max
- Contact Material: Copper
- Length: 4.11" (104.4 mm)
- Rating: 100 Amps

RS PRO Crocodile Clips, Copper Contact, 100A

RS Stock No.: 0205389



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Crocodile Clips



Product Description

- RS heavy duty alligator clips with screw and crimp terminations, are ideal for testing and battery connection purposes and other applications that require a heavy duty alligator clip.
- RS Electric Heavy Duty, General Purpose, Crocodile and Alligator Clips
- A concise offering of steel and copper alligator and crocodile clips from RS suitable for applications including grounding clips, test meters clips, battery terminal connection and many others that require a durable and hardwearing alligator or crocodile clip.

General Specifications

Material	Copper, Spring: Steel
Product Name	Crocodile Clips
Type	Automotive clip Heavy Duty Clip for Battery and Test Work
Insulated	No
Connection Type	Can be attached by crimp or screw connection

Commented [波幸1]:

Electrical Specifications

Current rating	100A
----------------	------

Mechanical Specifications

Jaw Opening ($\pm 10\%$)	1-1/16" (27mm) max
Contact Material	Copper
Insulation Material	No
Dimensions ($\pm 10\%$)	Overall length 4.11" (104.4 mm)


Approvals

Crocodile Clips



Standards Met	RoHS Compliant
Declarations	Reach

Spec Drawings Diameter

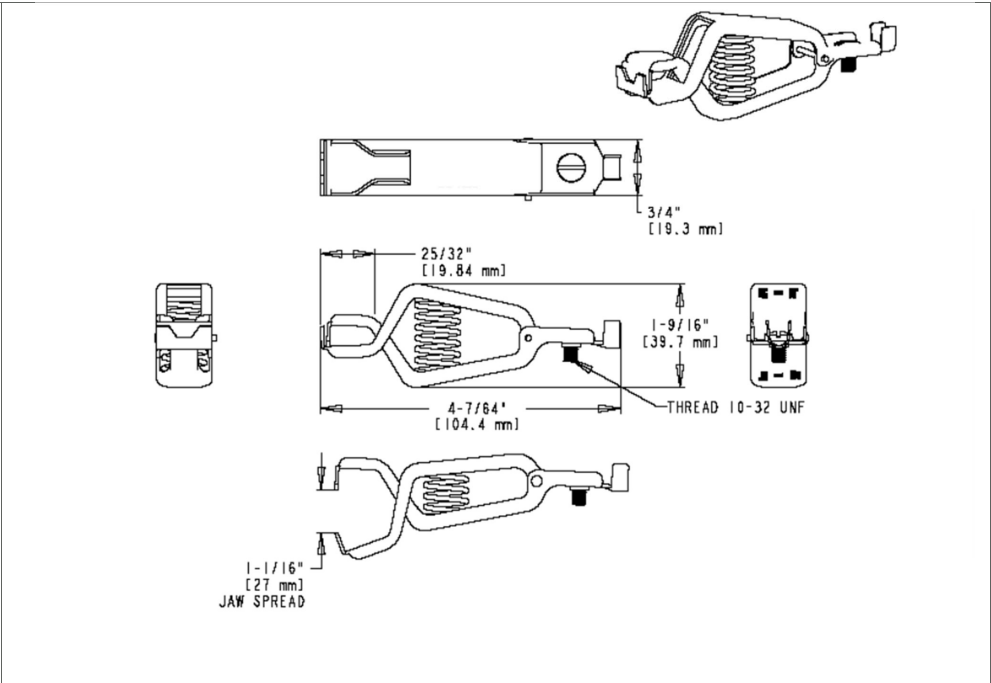

PRODUCT DIMENSION DRAWING AND ADDITIONAL INFORMATION