


PREVOST FILTRATION - KOMBINATIONEN VON EINHEITEN

Dreifachblock - Filterregler, Öler mit
Handventil

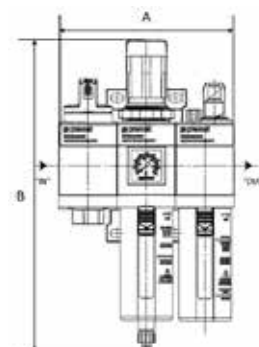

Max. Betriebsdruck

10 bar

Filterung (µm)

25.00

Art. Nr	IG	Durchfluß bei 6 bar (l/min) (ΔP= 1.00 bar)		Nettogewicht (Kg)	Abm. A (mm)	Abm. B (mm)
ATU VB2585100	G1/8	400	0.5 / 8.5	0	80	215
ATU VB2585101	G1/4	700	0.5 / 8.5	0	97	302
ATU VB2585102	G3/8	2000	0.5 / 8.5	2.546	97	302
ATU VB2585103	G1/2	3300	0.5 / 8.5	2.546	97	302