

MiniLynx 20W E27 BL368

Item No: 0025706

SYLVANIA

SpeciaLITE®




UV-A blacklight lamp with a radiation at 368nm which is widely accepted as the most important frequency for the attraction of insects.

Technical Assets

Dimensions (mm)

E27

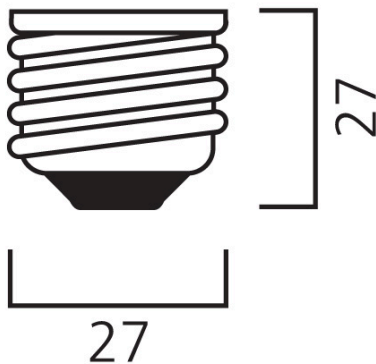

Photometrics

MiniLynx 20W E27 BL368

Item No: 0025706

SYLVANIA

General data

Product name	MiniLynx 20W E27 BL368
Technology	Fluorescent
Lamp shape	U shape
Cap/Base	E27
Lamp finish	Frosted/Coated
Fixture rating	Enclosed
General application	SPG
Operating temperature range (°C)	-10°C...+50°C
ETIM Class	EC002962
E-number FI	4940706

Optical data

UV-A intensity at 1m	32
Light colour	BL368 Blacklight
Adjustable chromaticity	N
Photobiological Risk Group	RG0

Electrical data

Power consumption (W)	20
Wattage (W)	20
Primary Supply/Product voltage - min (V)	230
Primary Supply/Product voltage - max (V)	240
Control gear required	No
Dimmable	No
Dimming method	N/A
Inrush Current (A)	5

Lifetime data

Average life (Nominal) (h)	8000
----------------------------	------

Physical data

Nominal Product Height (mm)	168
Nominal Product Diameter (mm)	54
Max. Lamp Diameter (mm) - D	52
Weight (kg)	0.102

Packaging

Product EAN number	5410288257068
Packaging single length / height (cm)	5.2
Packaging single width (cm)	5.2
Packaging single depth (cm)	17.4
DUN14 (inner)	15410288257065
Units per inner package	10
Packaging inner length / height (cm)	27.5
Packaging inner width (cm)	11.5
Packaging inner depth (cm)	19.5
Units per outer package	50
Packaging outer length / height (cm)	63.0
Packaging outer width (cm)	29.5
Packaging outer depth (cm)	22.5

Safety data

Lamp mercury content (mg)	2.5
Optimal operating condition (°C)	-10-50
Breakage cleaning instructions	Applicable
Recommendation for disposal at end of life	Applicable
Special purpose lamp	Yes
Intended purpose	Flykilling - Insect attraction
Suitable for household illumination	No
Safety message	Not suitable for household