




AS-Interface CompactLine module

CompactM8 4DI

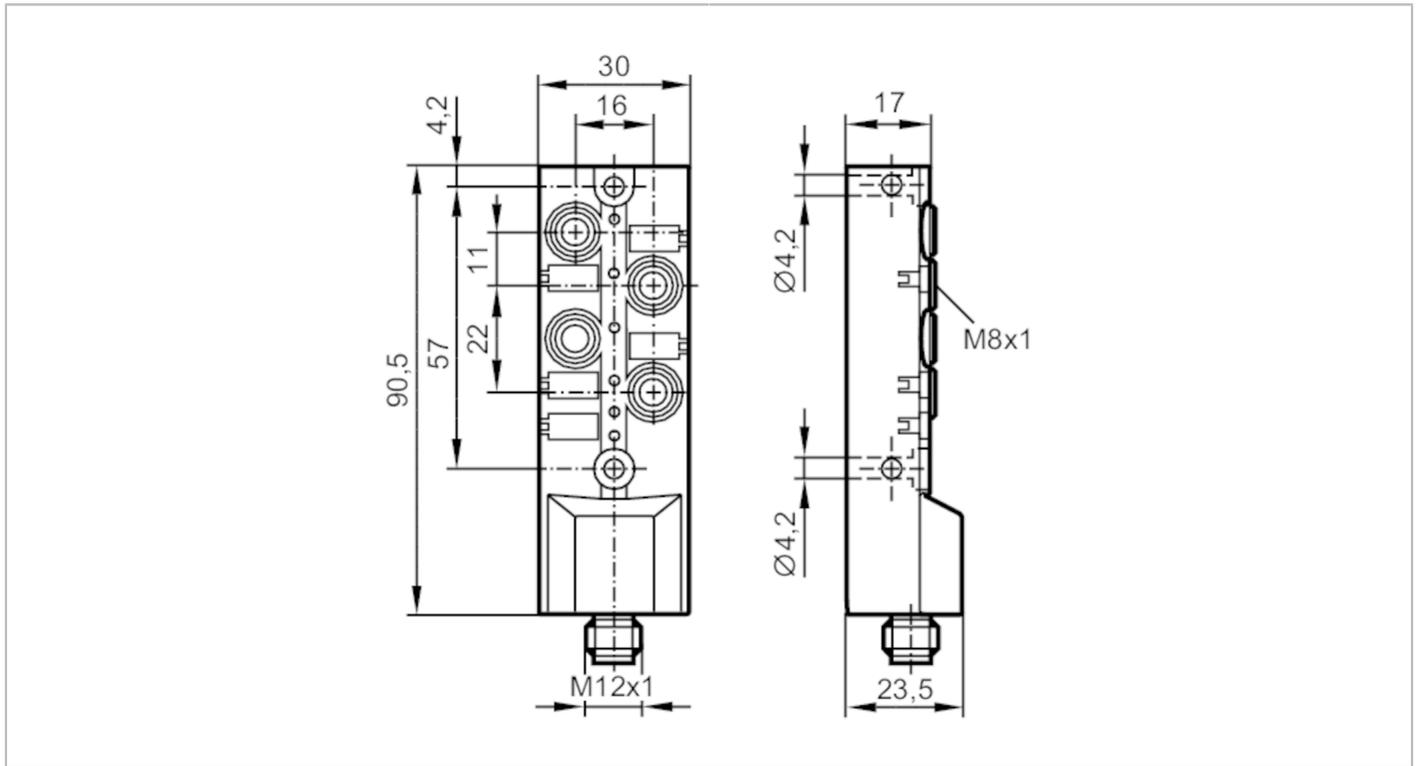

Application	
Application	field installation
Electrical data	
Operating voltage [V]	26.5...31.6 DC
Max. current consumption from AS-i [mA]	230
Inputs / outputs	
Number of inputs and outputs	Number of digital inputs: 4
Inputs	
Number of digital inputs	4
Input circuit of digital inputs	PNP; (type 2 according to IEC 61131-2)
Sensor supply of the inputs	AS-i
Power supply [V]	18...30; (DC)
Max. total current rating of inputs [mA]	180
Switching level high [V]	> 11
Digital inputs protected against short circuits	yes
Operating conditions	
Ambient temperature [°C]	-25...60
Storage temperature [°C]	-25...60
Max. relative air humidity [%]	90; (non condensing)
Max. height above sea level [m]	2000



AS-Interface CompactLine module

CompactM8 4DI

Protection	IP 65; IP 67; IP 68
------------	---------------------

Tests / approvals

EMC	EN 62026-2	
	EN 50581	
MTTF [years]		256
UL approval	power supply	Class 2

AS-i classification

AS-i version	2.11; 3.0					
Extended addressing mode	yes					
AS-i master profile	M2; M3; M4					
AS-i profile	S-0.A.E					
AS-i I/O configuration [hex]	0					
AS-i ID code [hex]	A.E					
AS-i certificate	100801					
Assignment of the data bits	data bit	D0	D1	D2	D3	
	input	I-1	I-2	I-3	I-4	
Assignment of the parameter bits	parameter bit	Designation				
	P0	not used				
	P1	peripheral fault indication	: 1	activated	/ 0	deactivated
	P2	not used				
	P3	not used				

Mechanical data

Weight [g]	110.5
Housing	rectangular
Type of mounting	backplane mounting
Dimensions [mm]	90.5 x 30 x 23.5
Materials	PBT

Displays / operating elements

Display	switching status	LED, yellow I1...I4
	operation	LED, green AS-i
	errors	LED, red

Electrical connection

Module connection	M12
-------------------	-----

Accessories

Items supplied	Label tags
	Protective caps: 2
Accessories (optional)	Protective cap: M8, E73005
	Flat cable insulation displacement connector: 1 m, round cable, E70583
	Flat cable insulation displacement connector: M12, E70096
	DIN rail adapter:, E73006




AS-Interface CompactLine module

CompactM8 4DI

Remarks	
Remarks	Do not connect any of the following points to an external potential: I-, I+, I1, I2, I3, I4
	The connections are electrically connected with the AS-i cable.
Pack quantity	1 pcs.

Electrical connection - AS-i


Connector: 1 x M12; coding: A

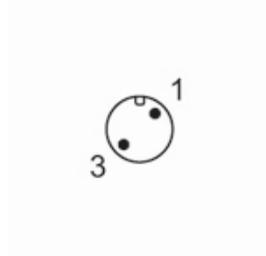

- 1 AS-i +
- 3 AS-i -

Electrical connection - Inputs

Connector: 4 x M8; coding: A

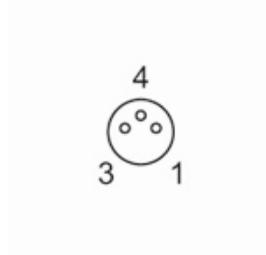

- 1 Inputs
- 3 Sensor supply L+
- 4 Sensor supply L-
- 1 data input