


Geberit Mapress Stainless Steel coupling (silicone-free)

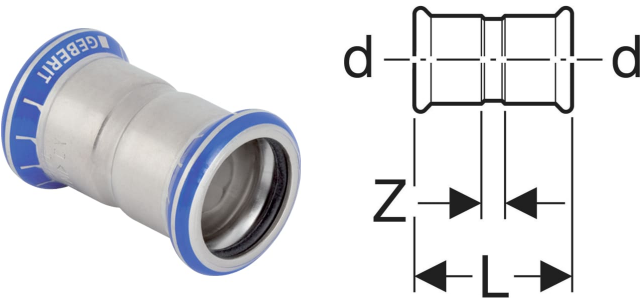

Example image

APPLICATION PURPOSES

- For cold and hot potable water
- For cooling and heating water without antifreeze agent
- For cooling and heating water with antifreeze agent
- For district heating water ≤ 120 °C
- For saturated steam ≤ 120 °C
- For service water and process water
- For treated water
- For grey and black water with a pH value ≥ 5.5

- For extinguishing water (wet)
- For extinguishing water (wet/dry, dry)
- For sprinklers (wet)
- For chemicals and technical liquids
- For compressed air (oil purity class 0–3)
- For negative pressure
- For inert gases (e.g. nitrogen)
- For industrial gases (e.g. acetylene, shielding gases)
- For technical building systems, industry and shipbuilding

CHARACTERISTICS

- Pressing indicator
- Leaky if unpressed
- Seal ring made of CIIR, black

TECHNICAL DATA

Product material CrNiMo steel 1.4401 (EN 10088)

Art. no.	DN	d, ø mm	L cm	Z cm
82002	12	15	4.8	0.8
82003	15	18	4.8	0.8
82004	20	22	5	0.8
82005	25	28	5.4	0.8

Art. no.	DN	d _g mm	L cm	z cm
82006	32	35	6.2	1
82007	40	42	7.1	1.1
82008	50	54	8.3	1.3
82009	65	76.1	12.7	2.1
82010	80	88.9	14.5	2.5
82011	100	108	17.4	2.6