




LED Special T34x93 E27 DIM 7.3W (60W) 806lm 827

Article number: 147066

BAI LED Special E27 7.3W (60W) 806lm 2700K T34x93mm 320° Dimmable LED-lamp

This LED series consists of lamps that are ideal as replacements for conventional lamps due to their compact design and high luminous flux. Ambient temperature range: -20°C to +40°C.

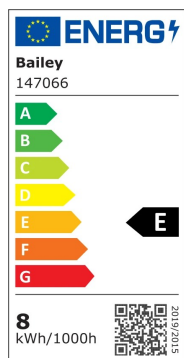

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED Special T34x93 E27 DIM 7.3W (60W) 806lm 827
Brand	Bailey
Productseries	LED Special
Producttype	T34X93 E27 827 CL

ETIM specifications

Socket	E27
Luminous flux [lm]	806 - 806
Nominal voltage [V]	220 - 240
Lamp power [W]	7.3 - 7.3
Colour temperature [K]	2700 - 2700
Diameter [mm]	34
Length [mm]	93
Dimmable	Yes
Lamp shape	Tube, single-ended
Beam angle [°]	320 - 320
Colour	White
Type of glass/cover	Clear
Lamp designation	Other
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	No
Rated luminous flux according to IEC 62612 [lm]	806
Power factor	0.8
Lamp efficacy [lm/W]	110
Nominal current [mA]	36 - 36
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	White
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	15000
Weighted energy consumption in 1000 hours [kWh]	8
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG1
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	Yes
Dimming phase cut-on (leading edge)	Yes
Dimming Touch and Dim	No
Dimming Zigbee	No

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	E
With twilight switch	No
Material of light bulb	Plastic

Alternative articles



146330
LED Ecobasic Stick T37 E27 9W
(61W) 820lm 827

Predecessor



146342
LED Special T32x90 E27 DIM
7.3W (60W) 806lm 827