




Technical data

AXK1104

Thrust needle roller bearing cages

VISUAL (S)

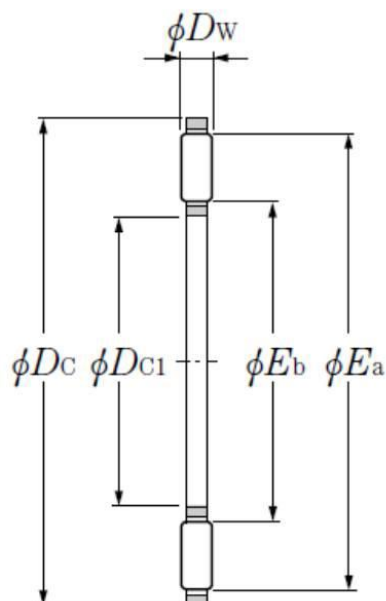

PRODUCT DEFINITION

Brand	NTN
Dc1 - Roller cage bore diameter	20 mm
Dc - Roller cage outer diameter	35 mm
Dw - Rolling element diameter	2 mm
Bearing ring (washer) AS	AS1104
Bearing ring (inner ring) WS	WS81104
Bearing ring (outer ring) GS	GS81104
Ea - Rollers reference outer diameter	31,3 mm
Eb - Rollers reference inner diameter	21,3 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

AXK1104

Thrust needle roller bearing cages

PRODUCT DEFINITION

Cage assembly mass	0,005 kg
--------------------	----------

PRODUCT PERFORMANCE

Ca - Dynamic axial load rating	13,2 kN
C0a - Static axial load rating	46,5 kN
Cua - Limit axial load rating	5,65 kN
N lim - Grease lubrication limit speed	2100 tr/min
N lim - Oil lubrication limit speed	8500 tr/min
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	120 °C

ESHOPDONOTDISPLAY

Tracepart	Oui/Yes
Reference	AXK1104
Image	NRBAXK_1.jpg, NRBAXK_3.jpg
Rolling element material	Acier 100Cr6



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15