

HI-VIS TROUSER

TR270

PRODUCT DESCRIPTION

Our Hi-Vis Trouser delivers durable protection with VXS+ woven yarn dyed fabric for improved colour fastness and colour durability. With a secure waistband, reinforced kneepad pockets, and pre-bent knees, it's built for comfort and flexibility in demanding environments.

Certified to APC 1 with an 8 cal/cm² ELIM rating, the TR270 integrates SafetyICON™ technology, keeping you informed about your protection level. Triple-stitched seams and reinforced hems ensure it stands up to the toughest tasks, wear after wear.

PRODUCT DETAILS

FITS: Male & Female

MALE SIZES: 30"-52" Short | Regular | Tall (TR270M)

FEMALE SIZES: 8-18 Regular (TR270F)

COLOUR: HVYellow



BOX TEST ARC RATING



EN STANDARDS



HI-VIS TROUSER

TR270

FEATURES & BENEFITS

- ✓ Waistband with concealed swivel front fastening
- ✓ Shaped raised back waistband for comfort when bending
- ✓ Large back belt loop to stop the belt rising
- ✓ 5 Self fabric belt loops
- ✓ Slanted hip pockets
- ✓ Spacious bellow pockets with concealed Velcro® flap closure
- ✓ Bellowed back pocket with contrast bar tacks
- ✓ Concealed Velcro® closure at pocket flap with Hex tab for increase grip and visibility
- ✓ All pockets Velcro® re-inforced for durability
- ✓ FR spiral zip for increased strength
- ✓ Gusset for ease of movement
- ✓ Internal knee pad pockets
- ✓ EN Heat seal icons to leg pocket
- ✓ Triple needle stitching to main seams
- ✓ SafetyICON with ELIM rating
- ✓ 70mm HEX FR reflective heat seal tape circling the lower leg

FABRIC SPECIFICATION:

- ✓ Weight: 260gms
- ✓ Weave Type: VXS+ Woven Yarn Dyed Fabric with FC Finish

PRODUCT CARE:

- ✓ Maximum washing temp 60°C
- ✓ Drying temperature: up to 60°C
- ✓ Ironing: Low temperature
- ✓ Dry clean permittable
- ✓ Do not use bleach



Concealed swivel front fastening



Spacious bellow pockets



Triple needle stitching to main seams



LIFETIME SEAM
GUARANTEE

HI-VIS TROUSER

WEARER FIT GUIDE - FEMALE

BODY MEASUREMENTS

SIZE	WAIST (cm / Inches)	HIP (cm / Inches)
6	65-70cm 26-28"	88-93cm 35-36"
8	70-75cm 28-30"	93-98cm 37-39"
10	75-80cm 30-32"	98-103cm 39-41"
12	80-85cm 32-33"	103-108cm 41-43"
14	85-90cm 33-35"	108-113cm 43-45"
16	90-95cm 35-37"	113-118cm 45-47"
18	95-100cm 37-39"	118-123cm 47-49"
20	100-105cm 39-41"	123-128cm 49-51"
22	105-110cm 41-43"	128-133cm 51-53"
24	110-115cm 43-45"	133-138cm 53-55"
26	115-120cm 45-47"	138-143cm 55-57"

WEARER HEIGHT

SIZE	HEIGHT (cm / Inches)
Short	156-164cm 5'1"-5'4"
Regular	164-172cm 5'4"-5'7"
Tall	172-180cm 5'7"-5'9"

WEARER INSIDE LEG

SIZE	INSIDE LEG (cm / Inches)
Short	74cm 29"
Regular	81cm 32"
Tall	86cm 34"

MEASURING GUIDE

Measurements must be taken wearing clothing usually worn underneath waterproof outerwear. The tape measure should be fairly loose and not pulled too tight.

- ✓ **BUST** - measure under the arms at the fullest part around the bust horizontally with arms by your side
- ✓ **WAIST** - measure around the natural waistline at the fullest part
- ✓ **HIP** - with the feet together measure around the fullest part of the hips
- ✓ **HEIGHT** - with bare feet together measure from the top of the head to the floor
- ✓ **INSIDE LEG** - in bare feet take the measurement from the top of the inside leg and measure down the inside leg to the floor


Once measurements are taken compare them to the fit guide measurement tables to find your Jacket and Trouser size.

When fitting the Trouser if the waist and seat measurements fall into different size categories then choose the larger size to ensure the trouser is not too close fitting.

If the height and inside leg measurements fall into different length categories then choose the jacket length based on the height measurement and the trouser length based on the inside leg measurement.

**These styles are historically perceived as FEMALE but can be worn by any person who's body measurements fit into the above tables.*

***Please note when using the measurement tables that all manufacturing tolerances and standard garment over-measures have been taken into account. This ensures any slight variances in manufacture or fabric shrinkage after washing will not affect the fit of the garments.*

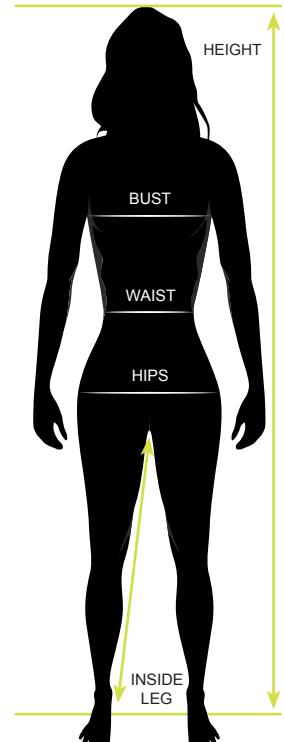

HI-VIS TROUSER

WEARER FIT GUIDE - MALE

BODY MEASUREMENTS

SIZE	WAIST (cm / Inches)	
26	70-75cm	28-30"
28	75-80cm	30-32"
30	80-85cm	32-33"
32	85-90cm	33-35"
34	90-95cm	35-37"
36	95-100cm	37-39"
38	100-105cm	39-41"
40	105-110cm	41-43"
42	110-115cm	43-45"
44	115-120cm	45-47"
46	120-125cm	47-49"
48	125-130cm	49-51"
50	130-135cm	51-53"
52	135-140cm	53-55"
54	140-145cm	55-57"

WEARER HEIGHT

SIZE	HEIGHT (cm / Inches)	
Short	164-172cm	5'4"-5'7"
Regular	172-180cm	5'7"-5'9"
Tall	180-188cm	5'9"-6'2"

WEARER INSIDE LEG

SIZE	INSIDE LEG (cm / Inches)	
Short	76cm	30"
Regular	81cm	32"
Tall	86cm	34"

MEASURING GUIDE

Measurements must be taken wearing clothing usually worn underneath waterproof outerwear. The tape measure should be fairly loose and not pulled too tight.

- ✓ **CHEST** - measure under the arms at the fullest part around the chest horizontally with arms by your side
- ✓ **WAIST** - measure around the natural waistline at the fullest part
- ✓ **SEAT** - with the feet together measure around the fullest part of the hips
- ✓ **HEIGHT** - with bare feet together measure from the top of the head to the floor
- ✓ **INSIDE LEG** - in bare feet take the measurement from the top of the inside leg and measure down the inside leg to the floor

Once measurements are taken compare them to the fit guide measurement tables to find your Jacket and Trouser size.

When fitting the Trouser if the waist and seat measurements fall into different size categories then choose the larger size to ensure the trouser is not too close fitting.

If the height and inside leg measurements fall into different length categories then choose the jacket length based on the height measurement and the trouser length based on the inside leg measurement.

**These styles are historically perceived as MALE but can be worn by any person who's body measurements fit into the above tables.*

***Please note when using the measurement tables that all manufacturing tolerances and standard garment over-measures have been taken into account. This ensures any slight variances in manufacture or fabric shrinkage after washing will not affect the fit of the garments.*

