


Moulded Reed Switch - Rectangular - Normally Open Contacts
Part Number : PPS 24
Product Data Sheet

PICTURE



DIMENSIONS

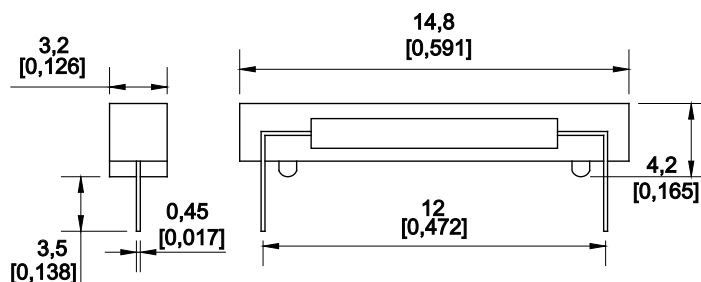

Drawings not to scale
 All dimensions in mm nominal

✓ RoHS Compliant

SPECIFICATION

Contact Form / Style		Normally Open
Switching Voltage	Max Volts AC	24
Switching Current	Max Amps	0.1
Switching Capacity (Resistive)	Max W/VA	1.0
Switching Distance (Typical)	mm	dependant on magnet
Contact resistance	Max mOhm	200
Operating Temperature	Celsius	-25° -70°
Storage Temperature	Celsius	-25° -70°
Case Material		Polypropylene

Applications Include

- Position and limit sensing.
- Linear actuators.
- Consumer electronics activation.
- Automated production lines.

Options

- Colour: Standard = Blue housing.
Also available Black housing.
- Various AT ratings
- Please contact our technical sales team if you have a specific requirement

Rev. No.

2

Revision Note

Datasheet update

Date

02-03-12

Signature

ML



ISO 9001:2008
 Certificate No. FM21080

As part of the company policy of continued product improvement, specifications may change without notice. Our sales office will be pleased to help you with the latest information on this product range and the details of our full design and manufacturing service. All products are supplied to our standard conditions of sale unless otherwise agreed in writing.

Phone : +44 (0)1255 862236

www.assemtech.co.uk

Fax: +44 (0)1255 862014

©2012 Copyright Assemtech Europe Ltd, Unit 7, Rice Bridge Industrial Estate, Thorpe - Le - Soken, Essex, CO16 0HL, ENGLAND.