



Part Number : [1200655103](#)


Product Description : Micro-Change (M12)
Single-Ended Cordset, 12 Poles, Female (90°)
to Pigtail, 26 AWG, PUR Cable, 10.0m (32.81')
Length

Series Number : 120065

Status : Active

Product Category : Circular Industrial
Cordsets

Engineering Number : 80C001H45M100

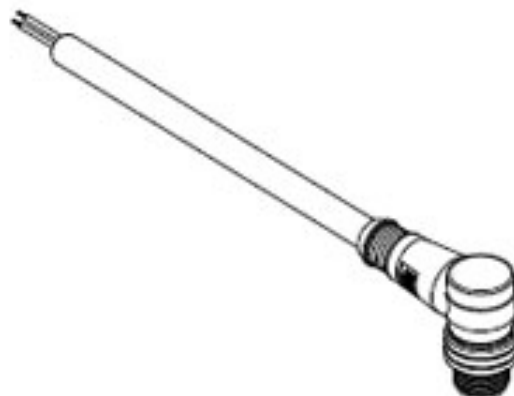

Documents & Resources

Drawings

[1200655103_sd.pdf](#)

Product Environment Compliance

Compliance

China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Circular Industrial Cordsets
Series	120065
Description	Micro-Change (M12) Single-Ended Cordset, 12 Poles, Female (90°) to Pigtail, 26 AWG, PUR Cable, 10.0m (32.81') Length
IP Rating	IP67
Product Name	Micro-Change (M12)
Protocol	N/A
Type	Single Ended
UPC	884982007390

Agency

CSA	LR6837
-----	--------

Electrical

Current - Maximum per Contact	1.5A
Voltage - Maximum	30V AC/DC

Physical

Cable Diameter	6.00mm (.236")
Cable Length	10.0m (32.81')
Color - Cable Jacket	Black
Connector End A	Micro-Change (M12)
Connector End B	Pigtail
Coupling Style	Threaded
Gender	Female-Pigtail
Keyway	Single
LED Indicator	None
Material - Cable Jacket	PUR
Material - Connector Body	PUR
Material - Contact	Copper Alloy

Material - Coupling Nut	Nickel-plated Brass
Material - O-Ring	Fluoro-elastomer
Material - Plating Mating	Gold
Orientation	90° to Pigtail
Poles	12
Temperature Range - Operating	-25° to +90°C
Wire/Cable Type	UL 20549
Wire Size (AWG)	26

This document was generated on Mar 27, 2025