


## FEATURES

- **Heavy Duty Design:** Supports a tensile strength of 114 kg, ensuring secure fastening of large cable bundles.
- **Nylon Material:** Offers durability and resistance to wear, suitable for long-term use.
- **UL 94 V-2 Fire Behaviour:** Provides a level of flame retardancy, enhancing safety in various applications.
- **Maximum Bundle Diameter of 216 mm:** Accommodates large cable bundles, increasing versatility.
- **730 mm Length:** Allows for bundling of extensive cable runs, reducing the need for multiple ties.
- **Temperature Resistance up to 85 °C:** Suitable for use in environments with elevated temperatures.
- **12.7 mm Width:** Ensures a strong grip on bundled cables, preventing slippage.

## RS PRO Heavy Duty Nylon Cable Tie, 730mm Length

RS Stock No: 656-111

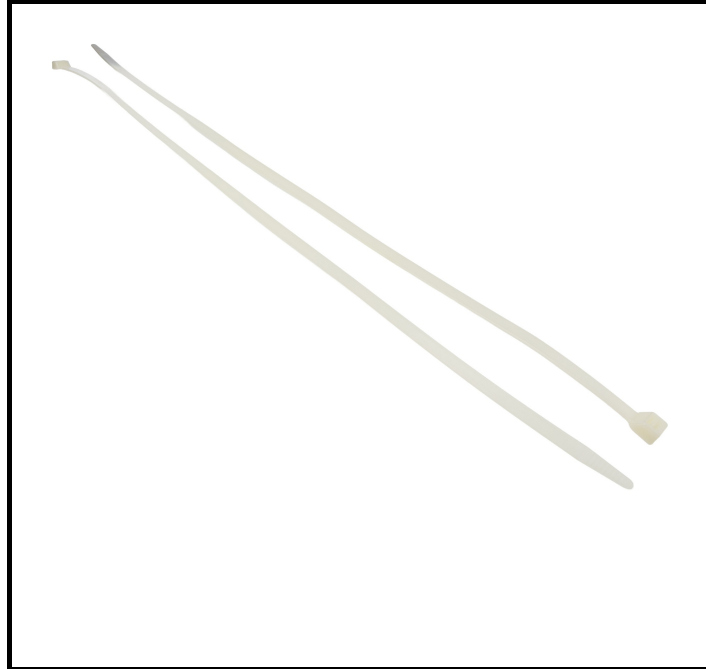

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

### Product Description

This RS PRO heavy duty cable tie is designed for securing and organising cables in demanding environments. Made from durable nylon, it is ideal for applications requiring high tensile strength and reliability. Its natural colour and robust construction make it suitable for both indoor and outdoor use, providing a secure bundling solution.

### General Specifications

Colour	Natural
Product Type	Cable Tie
Sub Type	Heavy Duty Cable Tie
Tensile Strength	114 kg

### Protection Category

Fire Behaviour	UL 94 V-2
UV Resistant	No

### Mechanical Specifications

Length	730 mm
Material	Nylon
Maximum Bundle Diameter	216 mm
Width	12.7 mm

### Operation Environment Specifications

Maximum Operating Temperature	85 °C
-------------------------------	-------

### Approvals

Standards/Approvals	ABS 15-TA1338482-PDA, CE 40022513, cULus E97527, DNV TAE00000US, LR 16-80006, RoHS, UL94V-2, VDE 40022513
---------------------	---

