

Series MANOSKOP® torque wrenches w.mount for insert tools

755




Product no. **50010010**
GTIN **4018754031627**
Model **755/10**

Label. MANOSKOP® torque wrench 755 20-100N·m 9 x 12 mm L. 318mm

- Properties.**
- clicking type with dual stop signal
 - for work on assembly lines or for repetitive production tasks.
 - no adjustment scale; therefore adjustment with test equipment is required, e.g. with the STAHLWILLE test devices No. 7707 W, SmartCheck or the perfectControl® calibration system No. 7794, or calibration systems No. 7706. 7791)
 - with holder for interchangeable insert tools
 - particularly slim design
 - handle and shaft made of square steel pipe
 - Further loading after clicking or loads in the opposite direction of operation (up to the max. measurement range of the torque wrench) do not affect the trigger mechanism, which protects it from damage
 - counter-clockwise tightening by turning the insert tool over
 - can be supplied pre-set at defined torque value and with certification (additional charge applies)
 - **accuracy $\pm 4\%$**

Technical drawing.

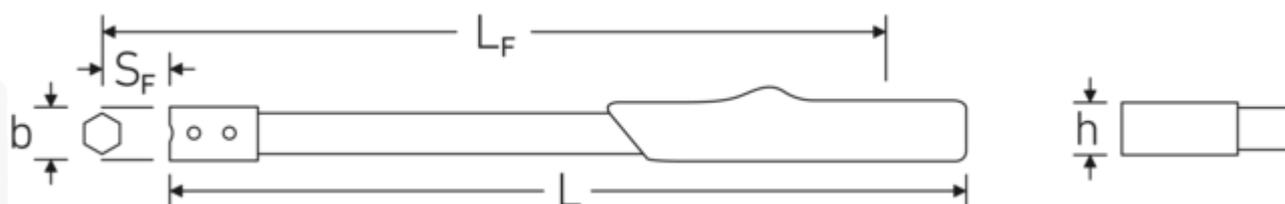

Technical attributes.

Measuring range N·m 20-100 N·m

Logistics data.

Depth mm (IFS) 320

Measuring range ft-lb	15-74 ft·lb	Width mm (IFS)	36
Width mm (b)	28 mm	Height mm (IFS)	30
Size	10	WEEE/ElektroG	nicht ear-pflichtig
Tool holder size [internal square]	9 x 12 mm	Length (packaged, mm)	345
Height mm (h)	24 mm	Width (packaged, mm)	57
Length mm (L)	318 mm	Height (packaging, mm)	57
LF	289 mm	Volume (packaged, dm3)	1.120905 dm3
MA N·m	20 N·m	Product no.	50010010
Nominal value N·m	100 N·m	Weight (gross, kg)	0,775
SF	17,5 mm	Weight PAP (kg)	0,000
		Weight PVC (kg)	0,066
		GTIN	4018754031627
		Country of origin AWR	GERMANY
		Region of origin	Nordrhein-Westfalen
		Customs tariff no.	82041100
		Packing standard	1
		Weight (g)	635 g

Variants.

Product no.	Model No. (ERP)	Description	GTIN
50010004	755/4	MANOSKOP® torque wrench 755 4-40N·m 9 x 12 mm L. 201mm	4018754031603
50010010	755/10	MANOSKOP® torque wrench 755 20-100N·m 9 x 12 mm L. 318mm	4018754031627
50010020	755/20	MANOSKOP® torque wrench 755 40-200N·m 14 x 18 mm L. 457mm	4018754031641
50010030	755/30	MANOSKOP® torque wrench 755 60-300N·m 14 x 18 mm L. 609mm	4018754031658

GTIN.





STAHLWILLE Eduard Wille GmbH

Lindenallee 27 · 42349 Wuppertal · Germany · Phone: +49 202 4791-0

info@stahlwille.de · www.stahlwille.com

© STAHLWILLE Eduard Wille GmbH, Wuppertal