



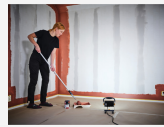

Rapid Work light The Painter

The LED work light The Painter has a light output of 2000 lumens that really lights up the work surface. The lamp's frosted glass minimises the risk of glare. The colour temperature of 6000 Kelvin is ideal for painting and wallpapering to help you see how the colours look in natural light. The Painter's adjustable lamp housing is also important in painting and wallpapering as it lets you direct the light. The heavy-duty flood light is easy to move around, and can also be mounted on a tripod (not included). The IP65 rating means that The Painter is fully dustproof and protected against water spray from all directions so you can use The Painter both indoors and outdoors. The lamp has a compact design, and is easy to store when you disassemble the stand. The Painter's properties also make it suitable for other renovation work.

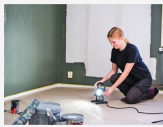

Attributes

- Light output of 2000 lumens
- Colour temperature of 6000 Kelvin, ideal for painting and wallpapering
- Frosted glass minimises glare
- Fully dustproof and protected against water spray from all directions (IP65)
- Handle makes it easy to move
- Easy to adjust the lamp housing's angle
- Can be put on a tripod (not included)
- Compact storage by disassembling the stand
- 2.5 meter power cord

Specifications

Number	5001737
Colour	-----
Dimensions (W x H x D)	20 x 266 x 165 mm
Weight	1190 g
Pallet quantity	105
EAN code	4051661045295