




ENGLISH

Datasheet


**Stock No: 144-1609**

**RS Pro RFT Socket**

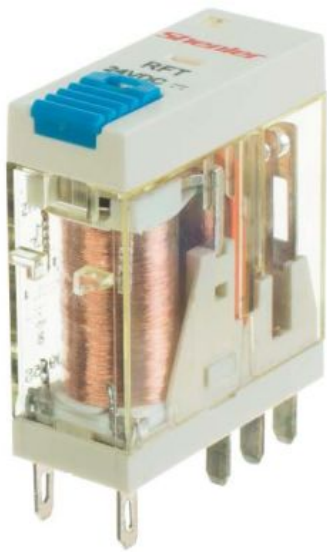

# Specifications:

**ENGLISH**

<b>RS Stock No</b>	<b>144-1609</b>	
<b>Characteristics</b>		
Nominal Load	Current	10A
	Voltage	300V
Dielectric Strength	Between Coil and Contact	4000 V/S
	Between Contacts	2500 V/S
Max. Tightening Torque	1.0 Nm	
Wire Size	20-14 AWG / 0.5-2.5mm <sup>2</sup>	
Ambient Temperature	-45-+85°C	
Unit Weight	27G	
Certification		
<b>Dimensions</b>	<b>Connection Diagram</b>	
