

GDS 18 V-LI

Specifications

Name	GDS 18 V-LI
Master-Order-No.	0 601 9A1 SOB
Internal ID	33409
Status	OK
Created	2009-04-17 (beu_hoerner_hoessler)

Description

Product line

- ▶ Trade / Industry

Title

- ▶ GDS 18 V-LI cordless impact wrench

Positioning

- ▶ The first 18-volt impact wrench with flexible battery system

User benefit

- ▶ Unique choice between the “Premium” (longer battery runtime) and “Compact” (less weight for even more comfortable work) batteries
- ▶ High torque and high impact rate (3,200 bpm) for fast work progress when driving screws in metal (up to M 16) and wood
- ▶ Very short design for perfect handling, even in the tightest spaces and overhead

Other features

- ▶ Innovative CoolPack batteries ensure optimum heat dissipation and therefore increase lifetime by up to 100% (cf. Li-Ion batteries without CoolPack)
- ▶ Bosch Electronic Cell Protection (ECP): protects the battery against overload, overheating and deep discharge
- ▶ Practical battery charge level indicator can be used at any time to find out how much energy is left in the battery

Title supplement for print

- ▶ with 4.0 Ah cordless battery

Title addition for online

- ▶ 4.0 Ah

Product category subdivision

- ▶ Cordless Impact Wrench

Technical data

Battery capacity	4 Ah
No-load speed	0 – 2.800 rpm
Charging time	45 mins
Weight incl. battery	1,7 kg
Torque, max. (hard screwdriving applications)	180 Nm
Rated impact rate	0 – 3.200 bpm

Linked digital objects

Product image



ID: #110669

Operating Instructions, Western Europe



ID: #200973

Operating Instructions, Eastern Europe



ID: #200973

Symbol image



ID: #7427




ID: #74532



ID: #226806 ID: #5781

Dimensional drawing

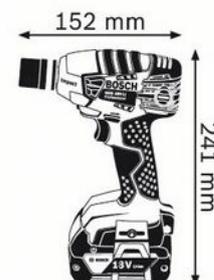

ID: #114906

GDS 18 V-LI

Technical data

Length	152 mm
Height	241 mm
Battery voltage	18 V
Bit holder	1/2" external square

Screw diameter

Screw diameter	M 6 – M 16
----------------	------------

Noise/vibration information

Noise level	The A-rated noise level of the power tool is typically as follows: Sound pressure level 96 dB(A); Sound power level 107 dB (A). Uncertainty K= 3 dB.
-------------	--

Functions

- ▶ Right-hand/left-hand rotation
- ▶ Electronic
- ▶ Softgrip

CSO Selection

Order No. 1	0 601 9A1 S75
EAN-Code	3165140726634
Scope Of Supply	AL 1860 CV quick charger (2 607 225 324) L-BOXX 136 (1 600 A00 1RR) 1/1 L-BOXX inlay for tool and charger (1 600 A00 2VC) 2 x 4.0 Ah Li-Ion batteries (1 600 Z00 038)
Baretool number	3601JA1S00
SOL Date	01.01.2013

Order No. 2	0 601 9A1 S06
EAN-Code	3165140625326
Scope Of Supply	Battery and charger not included L-BOXX 136 (1 600 A00 1RR) 1/1 L-BOXX inlay for tool and charger (1 600 A00 2VC)
Baretool number	3601JA1S00
SOL Date	01.01.2013

Linked digital objects

Application image



ID: #110675



ID: #110682



ID: #110677

15.11.2016 15:50:15

RBGB - Großbritannien - English