

Accessories 1 1/2"

K9867S




Drive: 1 1/2" DIN 3121-H25
 Maximum angle 35°
 Finish: forged phosphated
 Material: CHROME-MOLYBDENUM

K9867S	7314150133932	1	1 1/2	1 1/2	154.2	88.9	K560F-8	4050

Sledge hammer spanner

7444SG-Z

Ring-end sledge hammer spanner.
 DIN 7444
 Finish: steel grey
 Material: SPECIAL STEEL, forged.
 Short and strong profiled handle and striking end for heavy-duty operations in shipyards, railways, heavy industries etc.

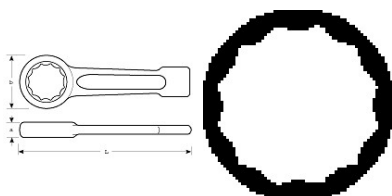

					L mm	A mm	B mm	g
7444SG-Z-1.1/16		7314150132546	1	1 1/16	180	16	46	350
7444SG-Z-1.1/8		7314150132553	1	1 1/8	180	16	46	350
7444SG-Z-1.3/16		7314150132560	1	1 3/16	190	17	52	400
7444SG-Z-1.1/4		7314150132577	1	1 1/4	190	17	52	450
7444SG-Z-1.5/16		7314150132584	1	1 5/16	190	17	52	450
7444SG-Z-1.3/8		7314150132591	1	1 3/8	205	18	58	750
7444SG-Z-1.7/16		7314150132607	1	1 7/16	205	18	58	750
7444SG-Z-1.1/2		7314150132614	1	1 1/2	205	18	58	750
7444SG-Z-1.5/8		7314150132621	1	1 5/8	230	20	66	850
7444SG-Z-1.11/16		7314150132638	1	1 11/16	230	20	66	850
7444SG-Z-1.3/4		7314150132645	1	1 3/4	240	22	74	1050
7444SG-Z-1.13/16		7314150132652	1	1 13/16	240	22	74	1050
7444SG-Z-1.7/8		7314150132669	1	1 7/8	240	22	74	1050
7444SG-Z-2		7314150132676	1	2	255	24	80	1250
7444SG-Z-2.1/16		7314150132683	1	2 1/16	255	24	80	1250
7444SG-Z-2.1/8		7314150132690	1	2 1/8	270	25	86	1550
7444SG-Z-2.3/16		7314150132706	1	2 3/16	270	25	86	1550
7444SG-Z-2.1/4		7314150132713	1	2 1/4	270	25	86	1550
7444SG-Z-2.3/8		7314150132720	1	2 3/8	280	26	93	1650
7444SG-Z-2.9/16		7314150132744	1	2 9/16	300	30	102	2300
7444SG-Z-2.5/8		7314150132751	1	2 5/8	300	30	102	2300
7444SG-Z-2.3/4		7314150132768	1	2 3/4	330	33	110	2600
7444SG-Z-3		7314150132775	1	3	330	33	110	3350
7444SG-Z-3.1/8		7314150132782	1	3 1/8	360	36	126	3800
7444SG-Z-3.3/8		7314150132799	1	3 3/8	360	36	126	4200
7444SG-Z-3.1/2		7314150132805	1	3 1/2	390	40	142	5700
7444SG-Z-3.3/4		7314150132812	1	3 3/4	390	40	142	5700
7444SG-Z-3.7/8		7314150132829	1	3 7/8	420	45	155	6700
7444SG-Z-4		7314150132836	1	4	420	45	155	6700
7444SG-Z-4.1/8		7314150132843	1	4 1/8	420	45	155	6700
7444SG-Z-4.1/2		7314150132850	1	4 1/2	450	48	170	8500