
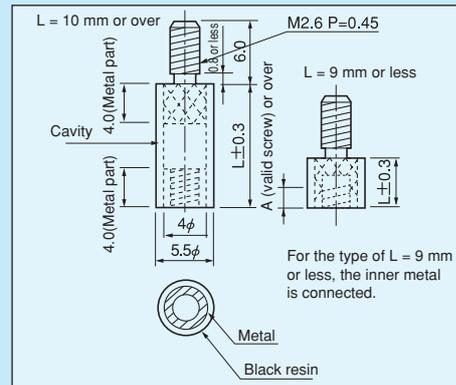


Spacer of metal resin type for printed board [2.6AP, 2.6AQ series] (100pcs/pack)

- The strength of this spacer is increased by filling metal in the resin.
- For the type of 10 mm or over, the upper part and the lower part are electrically insulated.
- For the type of 9 mm or less, the upper part and the lower part are electrically connected.
- Material: Resin part: PBT black (UL94V-0)
Metal part: Brass
- Finish: Nickel plating
- Operating temperature range: -40 to +125°C

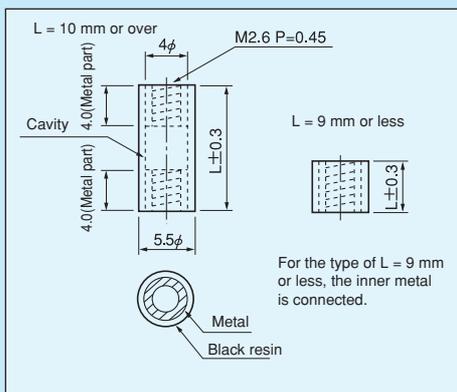

■ 2.6AP type (for M2.6)

Part number	L (mm)
2.6AP- 3	3
2.6AP- 4	4
2.6AP- 5	5
2.6AP- 6	6
2.6AP- 7	7
2.6AP- 8	8
2.6AP- 9	9
2.6AP-10	10
2.6AP-11	11
2.6AP-12	12
2.6AP-13	13
2.6AP-14	14
2.6AP-15	15
2.6AP-16	16
2.6AP-17	17
2.6AP-18	18
2.6AP-19	19
2.6AP-20	20
2.6AP-25	25
2.6AP-30	30
2.6AP-35	35
2.6AP-40	40
2.6AP-45	45
2.6AP-50	50

■ 2.6AQ type (for M2.6)

Part number	L (mm)	A (or over)
2.6AQ- 4	4	2
2.6AQ- 5	5	3
2.6AQ- 6	6	3
2.6AQ- 7	7	4
2.6AQ- 8	8	5
2.6AQ- 9	9	6
2.6AQ-10	10	
2.6AQ-11	11	
2.6AQ-12	12	
2.6AQ-13	13	
2.6AQ-14	14	
2.6AQ-15	15	
2.6AQ-16	16	
2.6AQ-17	17	
2.6AQ-18	18	
2.6AQ-19	19	
2.6AQ-20	20	
2.6AQ-25	25	
2.6AQ-30	30	
2.6AQ-35	35	
2.6AQ-40	40	
2.6AQ-45	45	
2.6AQ-50	50	