

LED light with switch Screw mounting 24-48 V DC



Model			
product brand name		SIVACON	
product designation		LED light	
design of the product		Screw fixing	
type of light source		LED not replaceable	
General technical data			
consumed active power of the light source		5 W	
type of voltage of the operating voltage		DC	
Protection class			
protection class IP		IP20	
Product details			
product component			
• ON/OFF switch			
• light sensor			
• socket outlet			
product feature magnetic		No	
Connections			
type of electrical connection for through-wiring		Plug-in connection	
Mechanical Design			
height		34 mm	
width		32 mm	
depth		34 mm	
length		351 mm	
fastening method		screw fixing	
net weight		0.2 kg	
material		plastic	
Approvals Certificates			
General Product Approval		other	Environment



[Miscellaneous](#)

[Confirmation](#)

[Environmental Confirmations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MR2201-1B>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MR2201-1B>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MR2201-1B

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

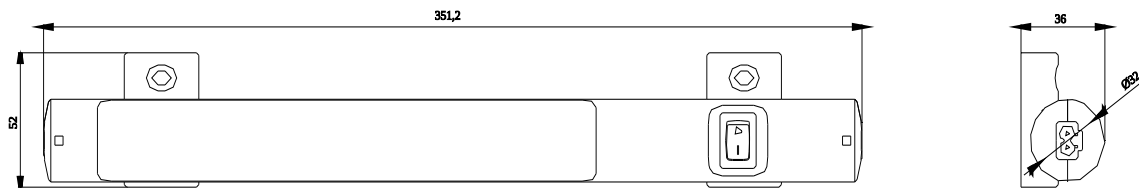

last modified:

5/24/2025 

