

Silicone lead wire 0.25mm²



Part NO: RGW-1617-2

Product Code: Silicone lead wire 0.25mm²

Product Description

Reference Standard

Customer's sample spec.and the general standard

Multi-construction

Single

Cable Construction

Conductor	Tinned Copper
Cross section	0.25mm ²
Construction(±0.003mm)	T0.08× 50
Standard Dia.	0.65
Jacket	silicone rubber
Thickness	0.65
Jacket Dia.(mm)	2.0±0.1
Color	Red: Black;

Marking

No Printing

PACKAGING


25M/ Reel

Suitable Reels/Box

RoHS GUIDELINE

We operate according to the following standards

Control Item	Standard	Testing Method	Testing Equipment
Cadmium content (Cd)	<0.01%	EN1122	ICP-AES
Lead content (Pb)	<0.1%	EPA3050B	ICP-AES
Mercury content (Hg)	<0.1%	EPA3052	ICP-AES
Chromium (VI) content	<0.1%	EPA3060(UN-VIS)	ICP-AES
Polybrominated Biphenyls(PBB)	Forbidden	GC/MS	
Polybrominated Diphenyl Ether (PBDE)	Forbidden	GC/MC	

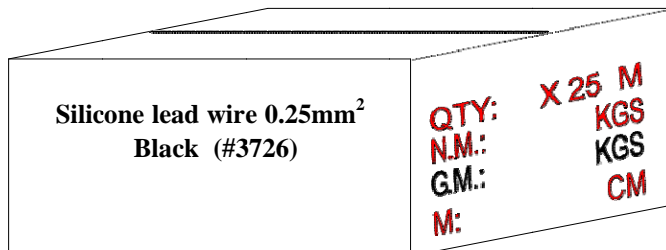

Revision History

A0-1

Design



Electrical Characteristics

Max.Conductor DC Resistance at 20°C (Ω /Km)	74
Min.Insulation DC Resistance at 20 °C (MΩ *Km)	>500
Rated Temperature(°C)	-55~+200
Rated Voltage (V)	300/500
Current Rating	1.4A

	Color	Product code	RS PART NO.
	Red	#3723	7482027
	Black	#3726	7482033

Label on Plastic bag

Product label

Silicone lead wire 0.25mm²
Color
25M
RoHS(2002/95/EC) Compliant
WW/YY

Color =Jacket Color
 WW=Week
 YY=Year

RS label



Date:	2011-11-08
Page:	1 / 1