

HELAVIA® bushes and strain relief in black polychloroprene rubber



HELAVIA®




type	artide number		type	artide number		type	artide number	
15-009	0253 0001 010	100	15-403	0256 0003 010	100	15-693**	0253 0112 010	50
15-043	0253 0004 010	100	15-405	0256 0005 010	100	15-721	0253 0003 010	100
15-045	0253 0005 010	100	15-410	0253 0051 010	100	15-737	0253 0080 010	50
15-049	0253 0008 010	50	15-411	0253 0052 010	50	15-747	0253 0083 010	50
15-083	0253 0013 010	25	15-412	0253 0053 010	50	15-748	0253 0084 010	50
15-130	0253 0014 010	50	15-538	0253 0064 010	100	15-751	0253 0091 010	50
15-131	0253 0015 010	50	15-561	0253 0065 010	100	15-756	0253 0085 010	50
15-147	0253 0016 010	50	15-579	0253 0066 010	50	15-760	0253 0113 010	100
15-159	0253 0017 010	100	15-592	0253 0070 010	50	15-781	0253 0087 010	50
15-164	0253 0018 010	50	15-596*	0253 0071 010	100	15-806	0253 0114 010	100
15-169	0253 0019 010	100	15-602**	0253 0072 010	50	15-821	0253 0115 010	100
15-170	0253 0020 010	100	15-608	0253 0073 010	100	15-822	0253 0117 010	100
15-171	0253 0021 010	100	15-625	0252 0319 010	100	15-832	0253 0118 010	100
15-172	0253 0022 010	100	15-633	0253 0077 010	50	15-833	0253 0119 010	100
15-190	0256 0010 010	100	15-642	0253 0078 010	100	15-834	0253 0120 010	100
15-306	0253 0057 010	100	15-643	0253 0079 010	50	15-836	0253 0121 010	100
15-318	0253 0058 010	100	15-649	0253 0075 010	100			
15-320	0253 0059 010	25	15-651	0253 0076 010	100			
15-329**	0253 0060 010	25	15-672	0253 0092 010	50			
15-354	0253 0061 010	100	15-680	0253 0095 010	100			
15-380	0253 0062 010	100	15-691**	0253 0110 010	100			
15-383	0253 0056 010	100	15-692**	0253 0111 010	50			
15-391	0253 0063 010	100						
15-401	0256 0001 010	100						
15-402	0256 0002 010	100						


Clamps for 15-412

16-900 0684 0054 000 100


* nitrile rubber **EPDM rubber

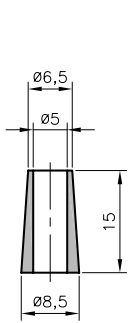


15-009
0253 0001 010

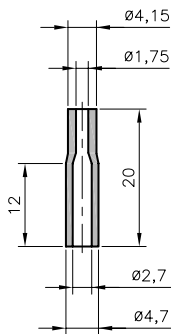


15-190
0256 0010 010

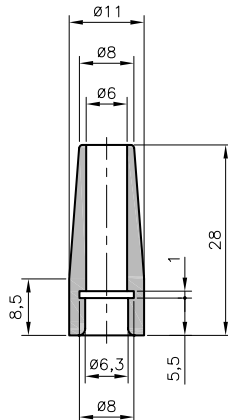


15-318
0253 0058 010

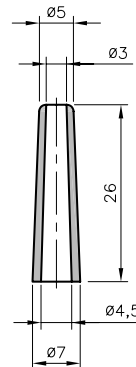


15-401
0256 0001 010

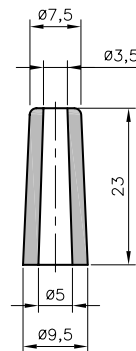


15-402
0256 0002 010

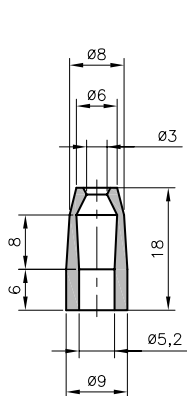


15-403
0256 0003 010

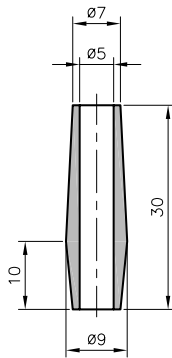


15-405
0256 0005 010

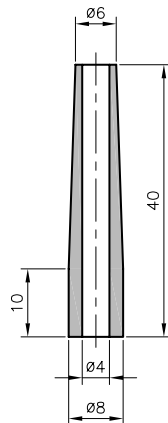


15-680
0253 0095 010

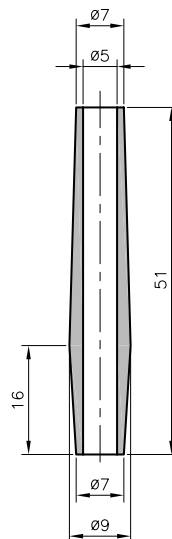

15-043
0253 0004 010

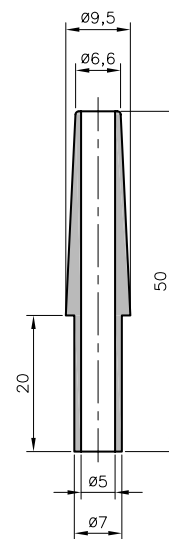

15-380
0253 0062 010

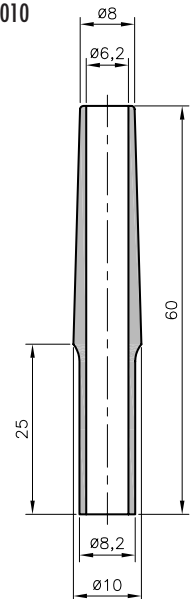


15-391
0253 0063 010


HELAVIA® bushes and strain relief
in black polychloroprene rubber




HELAVIA®

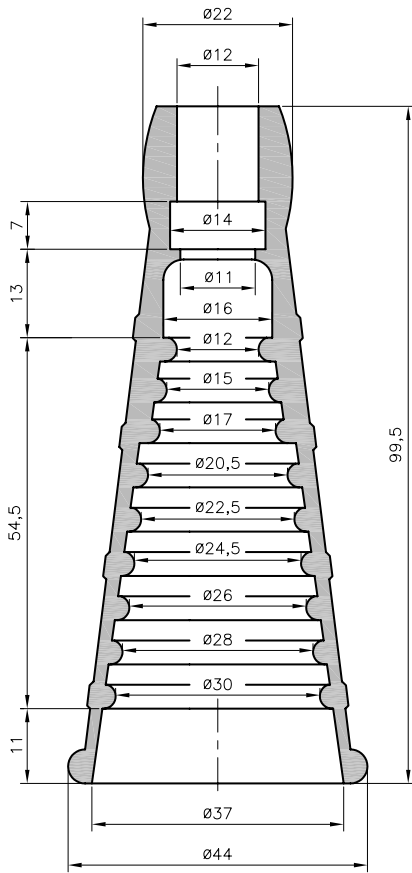


15-329
0253 0060 010

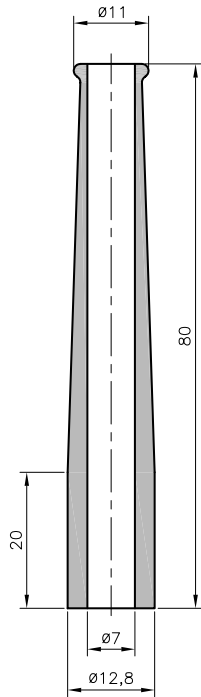


15-164
0253 0018 010

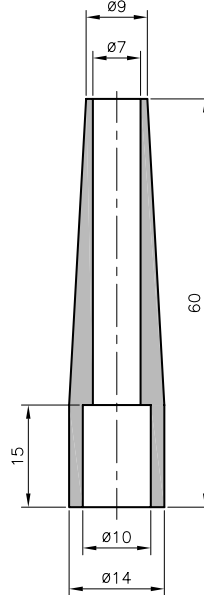


15-045
0253 0005 010

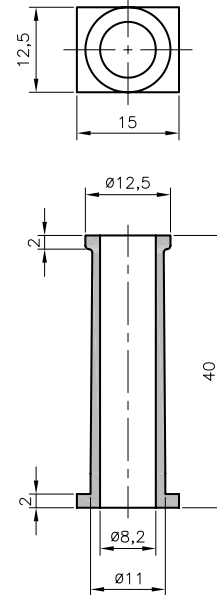


15-642
0253 0078 010

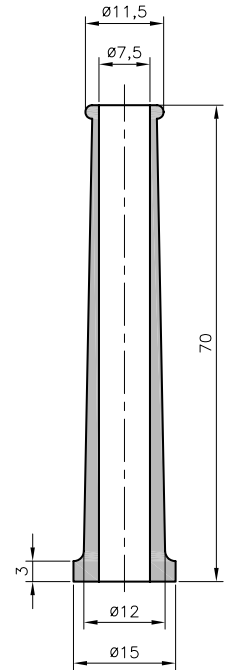


15-411
0253 0052 010

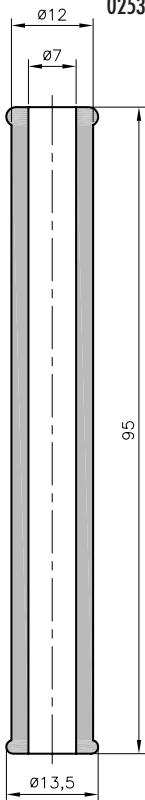


15-169
0253 0019 010

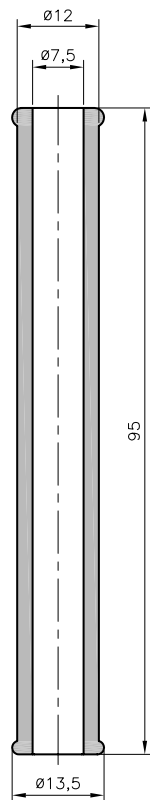


15-170
0253 0020 010

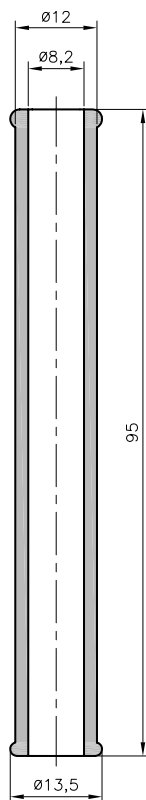


15-171
0253 0021 010

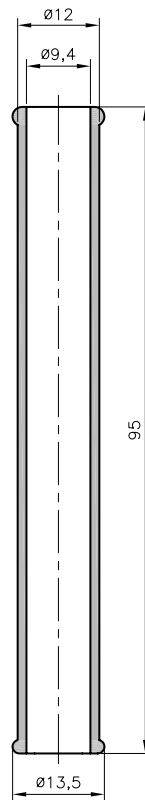

15-172
0253 0022 010

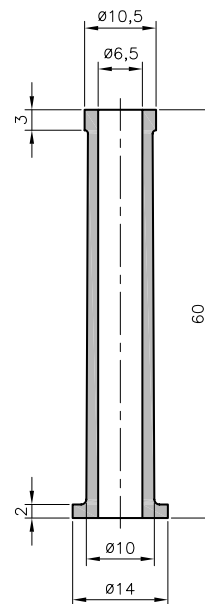

15-538
0253 0064 010

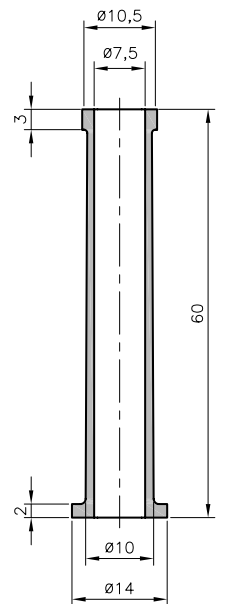



15-579
0253 0066 010



HELAVIA® bushes and strain relief
in black polychloroprene rubber




HELAVIA®

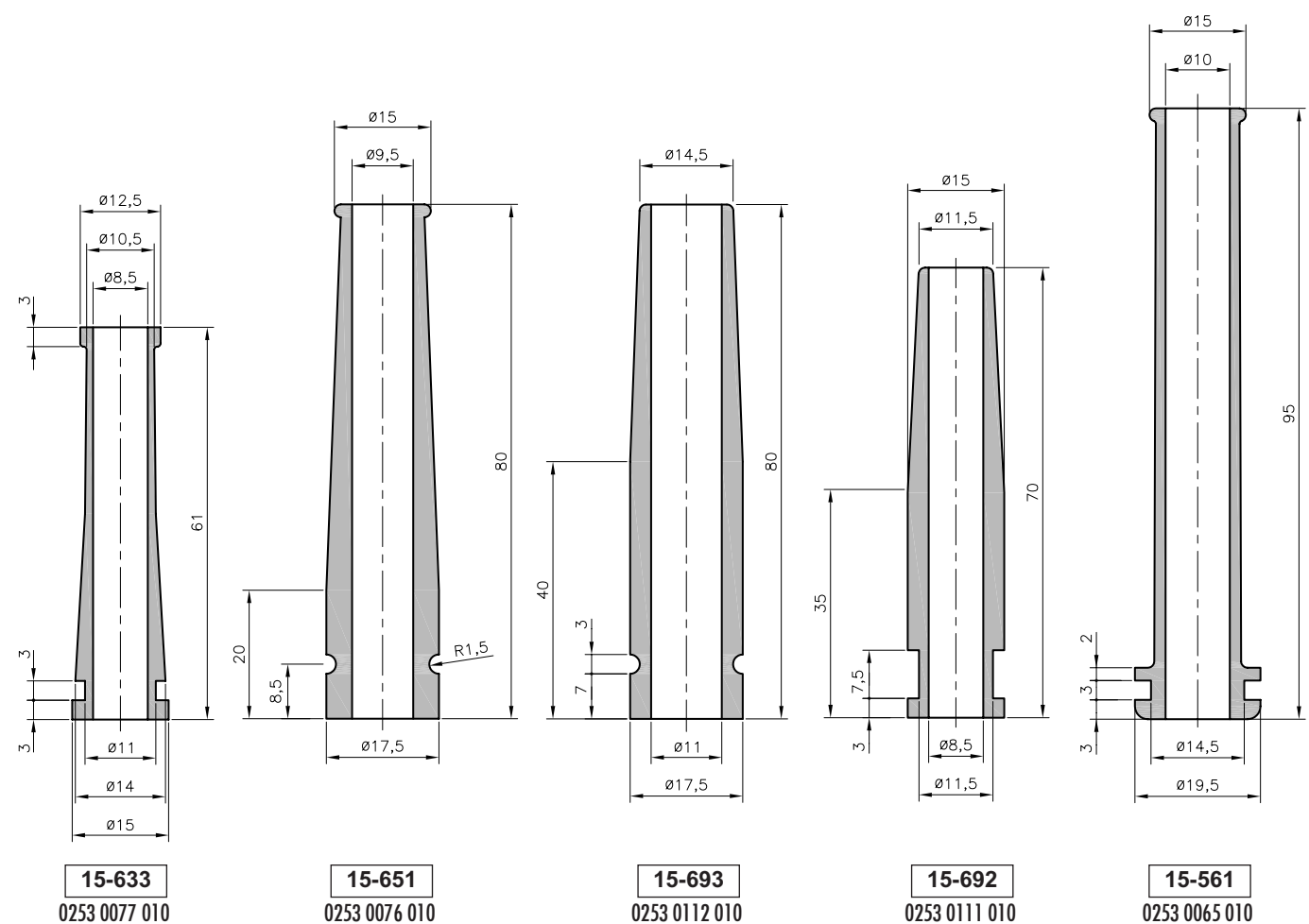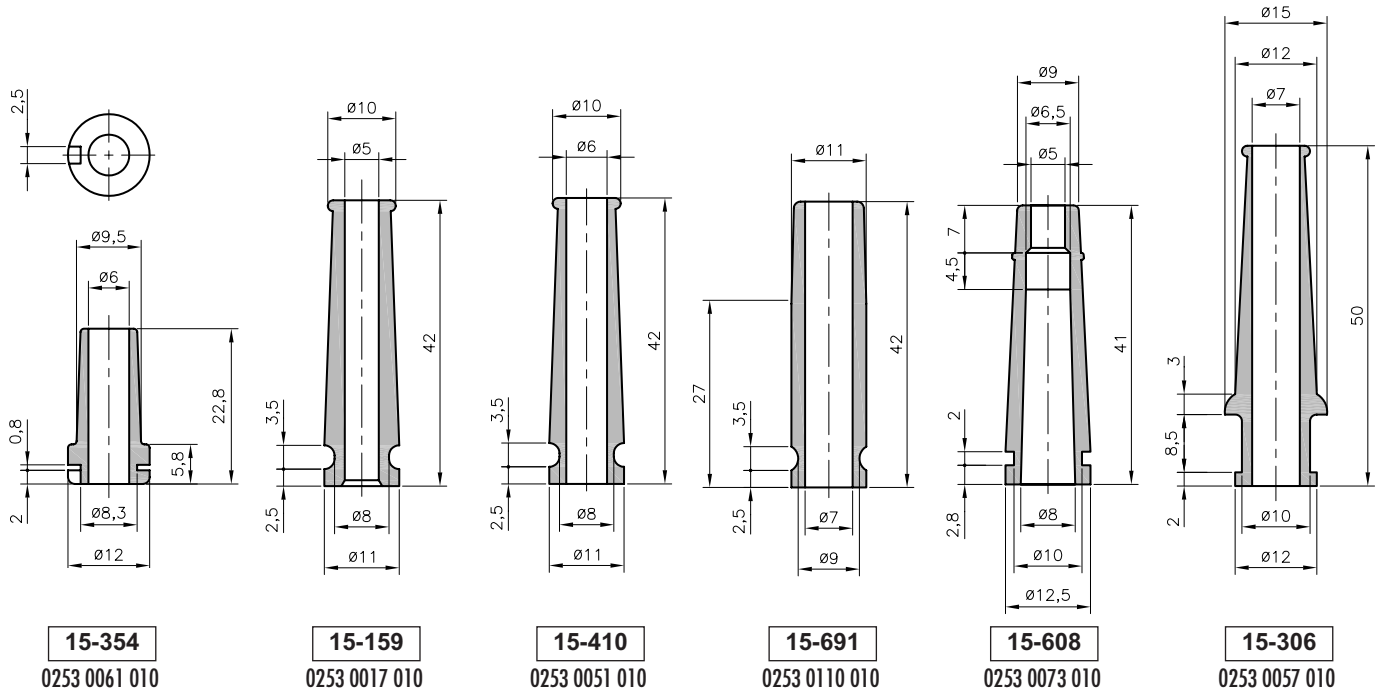


HELAVIA® bushes and strain relief
in black polychloroprene rubber




HELAVIA®

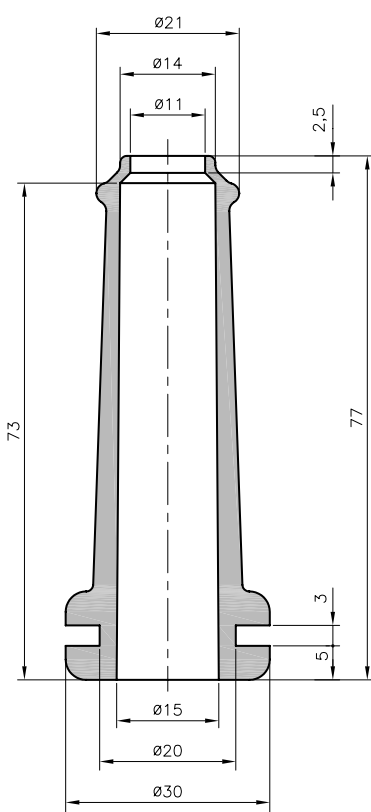


15-049
0253 0008 010

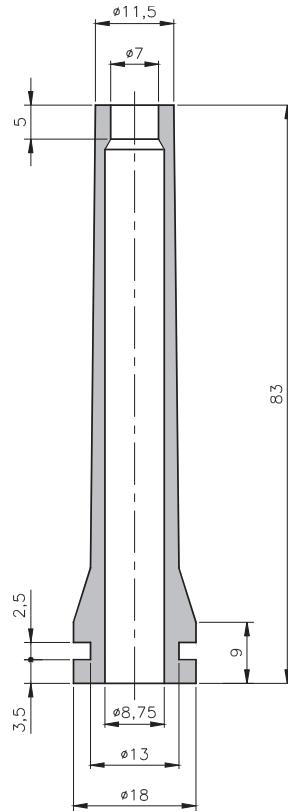


15-131
0253 0015 010

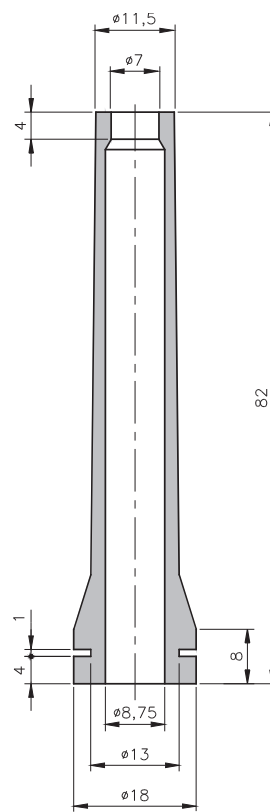


15-672
0253 0092 010

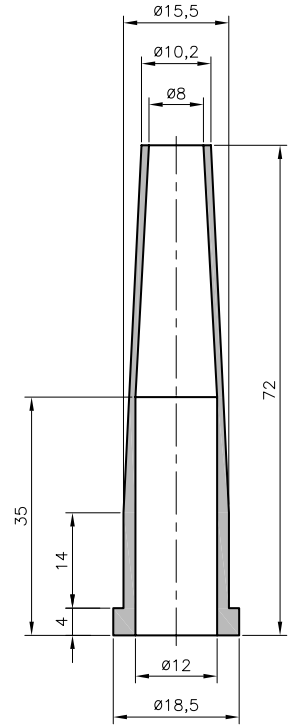


15-147
0253 0016 010

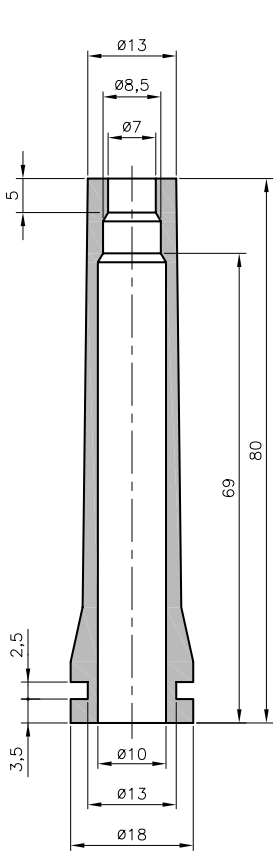


15-643
0253 0079 010

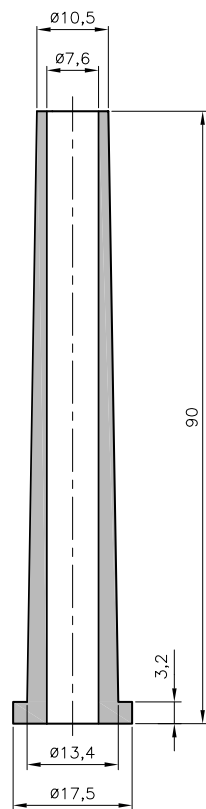


15-602
0253 0072 010

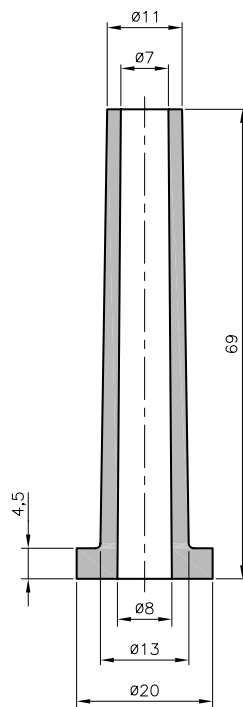

15-592
0253 0070 010

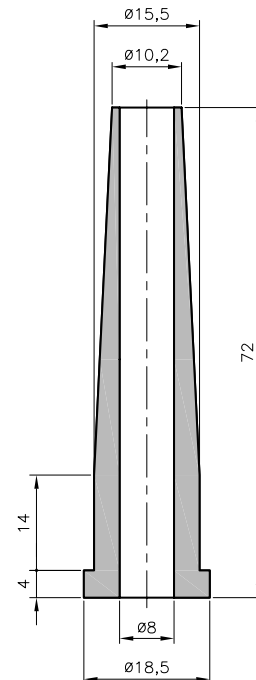

15-130
0253 0014 010

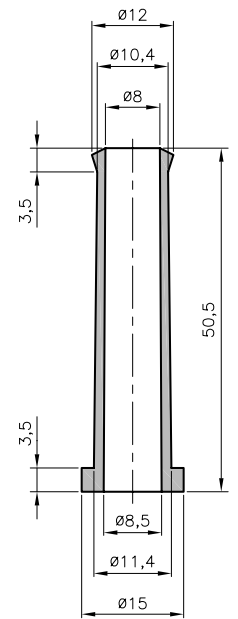


15-383
0253 0056 010




HELAVIA® bushes and strain relief
in black polychloroprene rubber




HELAVIA®

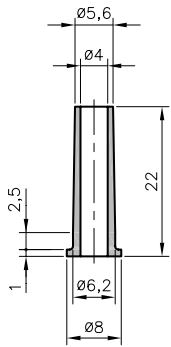


15-649
0253 0075 010

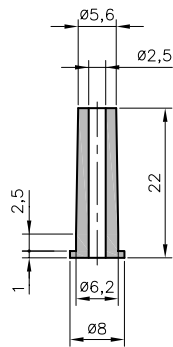


15-760
0253 0113 010

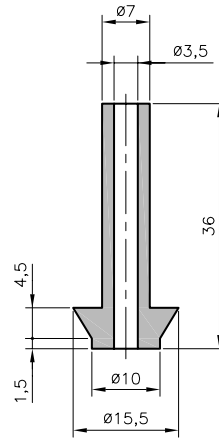


15-596
0253 0071 010

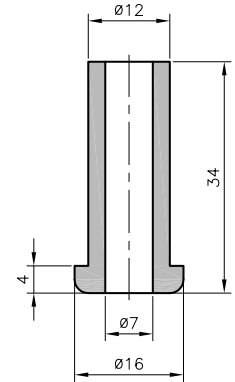


15-625
0252 0319 010

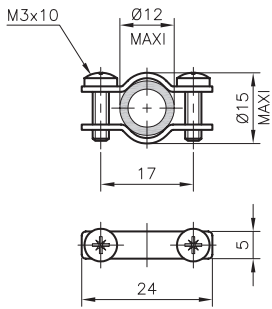


16-900
0684 0054 000

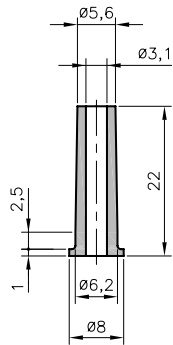


15-721
0253 0003 010

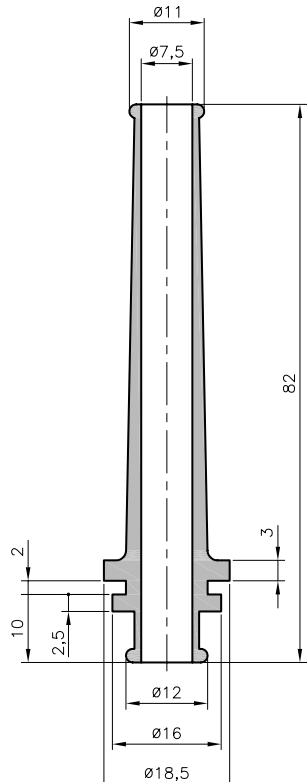


15-412
0253 0053 010

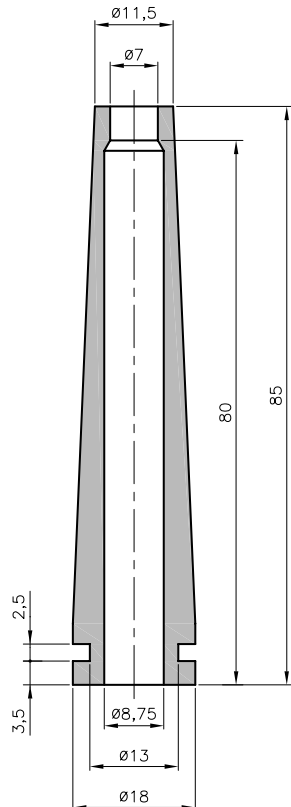

15-751
0253 0091 010

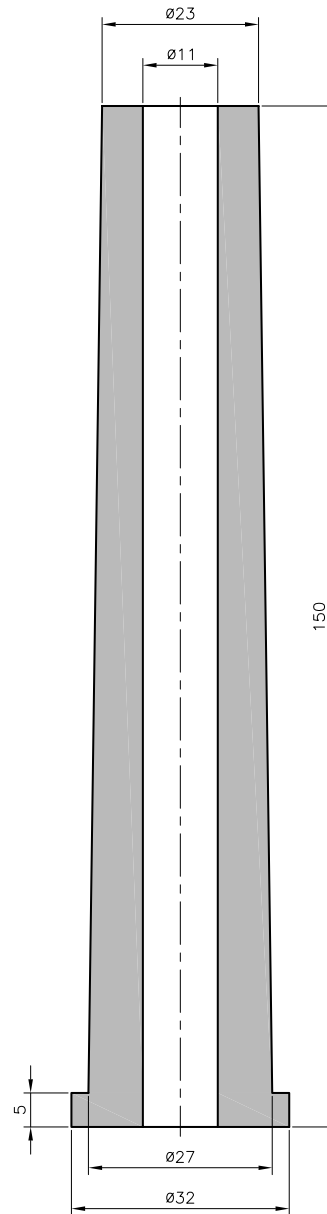

15-320
0253 0059 010

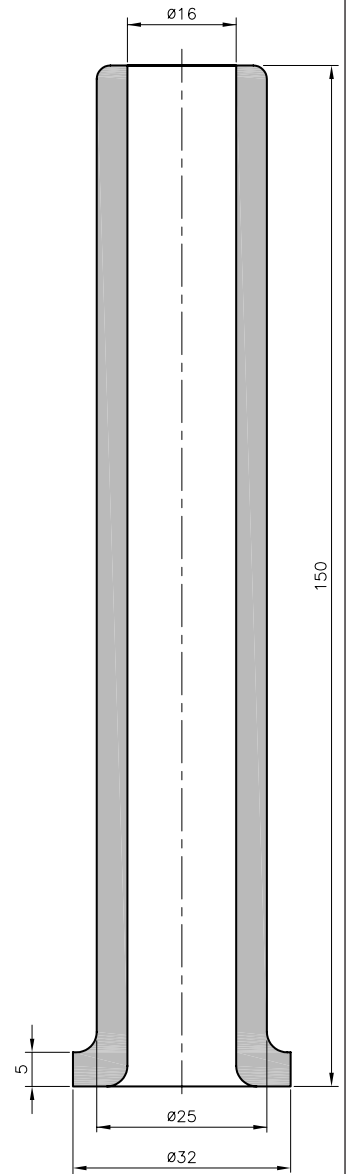


15-083
0253 0013 010




HELAVIA® bushes and strain relief
in black polychloroprene rubber




HELAVIA®

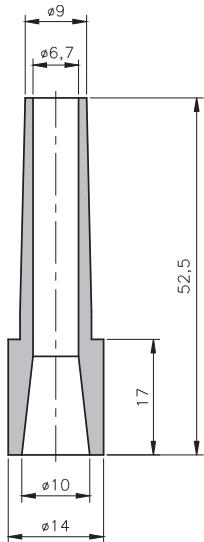


15-822
0253 0117 010

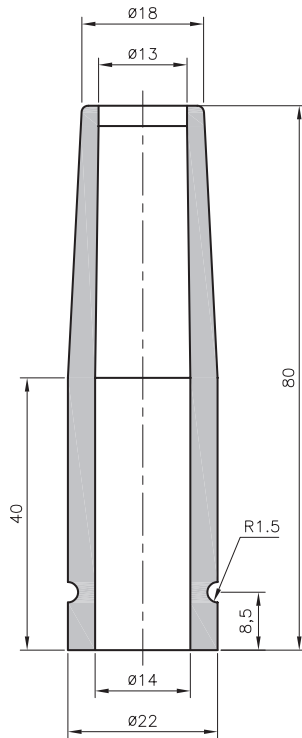


15-747
0253 0083 010

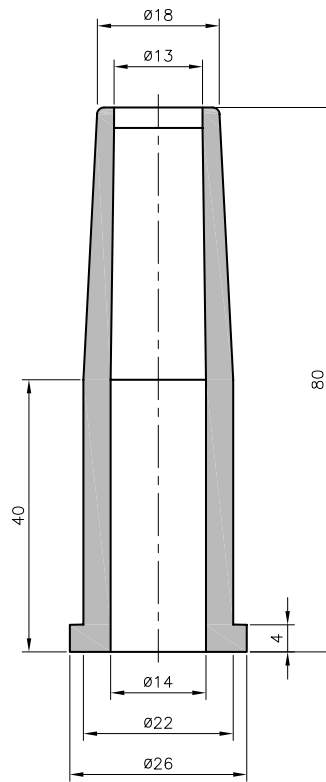


15-748
0253 0084 010

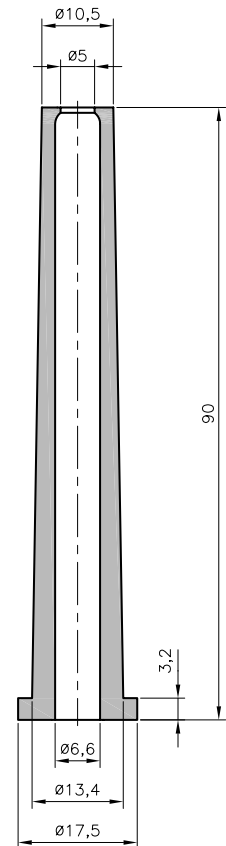


15-756
0253 0085 010

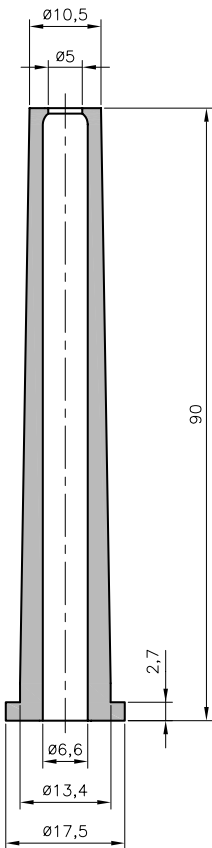


15-781
0253 0087 010

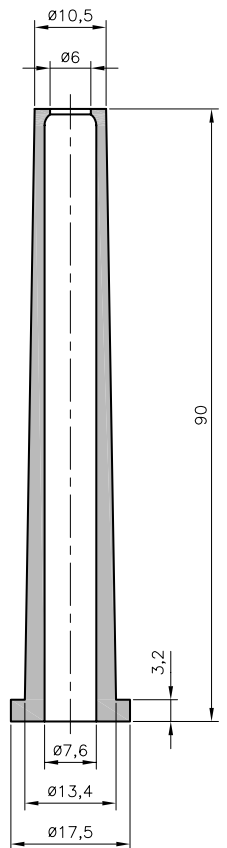

15-737
0253 0080 010

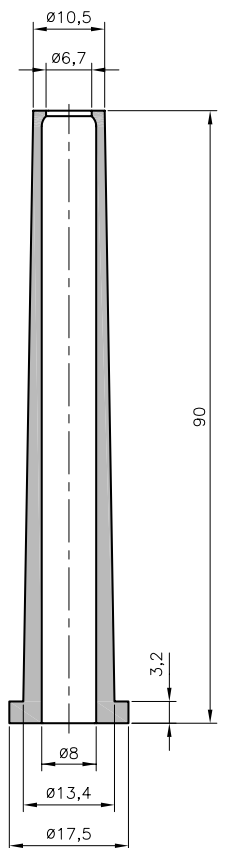

15-806
0253 0114 010

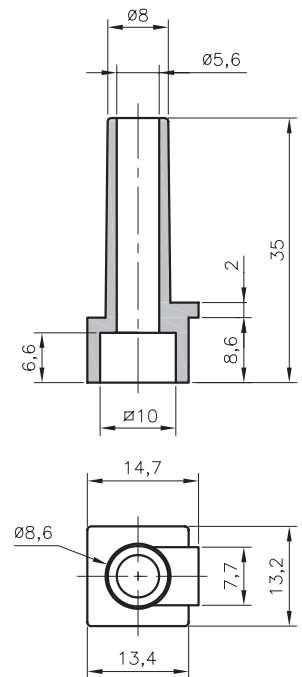


15-821
0253 0115 010




HELAVIA® bushes and strain relief
in black polychloroprene rubber




HELAVIA®

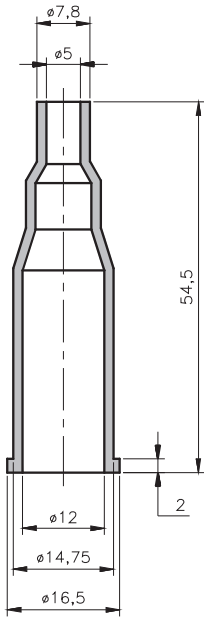


15-832
0253 0118 010

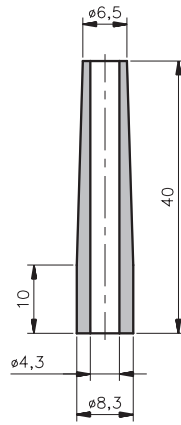

15-833
0253 0119 010

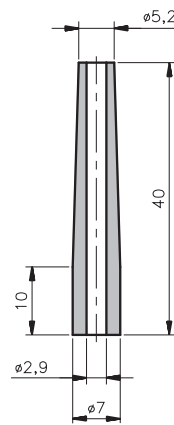

15-834
0253 0120 010

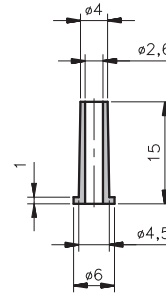

15-836
0253 0121 010