


FAST SANDING OF PAINT AND WOOD

EXPERT C470 Sandpaper

EXPERT

- ① Exceptional abrasion with Bosch Surface Structure
- ② Grain alignment during production ensures aggressive cut
- ③ Grain distribution optimised for high-speed sanding

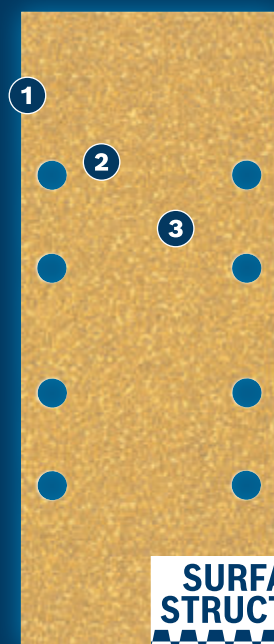

SURFACE
STRUCTURE

UP TO
2x*



* vs. Bosch C420




Video



BOSCH

EXPERT C470 SANDING DISCS

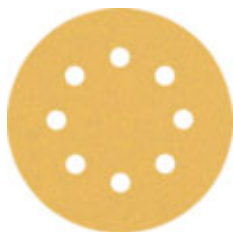

- Ideal for highly effective fast sanding of flat surfaces; to remove old paint; or to smooth, prepare and finish surfaces
- EXPERT Abrasives - the very best for all trades
- Up to 2x faster than Bosch C420 Sandpaper
- Just stick it on with hook and loop

PRODUCT PROPERTIES				ORDERING INFORMATION					
Disc diameter mm	Grit	Perforation	Packaging type	Pack quantity	Minimum order quantity	Barcode 4 059 952...	Part number		
115	40	8 holes	C1a	5	5	541 327	2 608 900 794		
115	60	8 holes	C1a	5	5	541 334	2 608 900 795		
115	80	8 holes	C1a	5	5	541 341	2 608 900 796		
115	120	8 holes	C1a	5	5	541 358	2 608 900 797		
115	180	8 holes	C1a	5	5	541 365	2 608 900 798		
115	240	8 holes	C1a	5	5	541 372	2 608 900 799		
115	320	8 holes	C1a	5	5	541 389	2 608 900 800		
115	400	8 holes	C1a	5	5	541 396	2 608 900 801		
125	40	8 holes	C1a	5	5	541 419	2 608 900 803		
125	60	8 holes	C1a	5	5	541 426	2 608 900 804		
125	80	8 holes	C1a	5	5	541 433	2 608 900 805		
125	100	8 holes	C1a	5	5	541 440	2 608 900 806		
125	120	8 holes	C1a	5	5	541 457	2 608 900 807		
125	180	8 holes	C1a	5	5	541 464	2 608 900 808		
125	240	8 holes	C1a	5	5	541 471	2 608 900 809		
125	320	8 holes	C1a	5	5	541 488	2 608 900 810		
125	400	8 holes	C1a	5	5	541 495	2 608 900 811		
125	40	8 holes	C0a	50	1	542 461	2 608 900 908		
125	60	8 holes	C0a	50	1	542 478	2 608 900 909		
125	80	8 holes	C0a	50	1	542 485	2 608 900 910		
125	100	8 holes	C0a	50	1	542 492	2 608 900 911		
125	120	8 holes	C0a	50	1	542 508	2 608 900 912		
125	150	8 holes	C0a	50	1	544 588	2 608 901 120		
125	180	8 holes	C0a	50	1	542 515	2 608 900 913		
125	220	8 holes	C0a	50	1	544 595	2 608 901 121		
125	240	8 holes	C0a	50	1	542 522	2 608 900 914		
125	320	8 holes	C0a	50	1	542 539	2 608 900 915		
125	400	8 holes	C0a	50	1	542 546	2 608 900 916		



BOSCH