


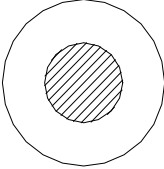

Product Name:	UL1429 20AWG
Product Discription:	UL1429 20AWG
Specification No.:	
Customer's Name:	

Description				
Rated Voltage:		150V		
Rated Temperature:		80℃		
Reference Standard:		UL758,UL1581		
Cross Section				
				
Marking				
E148000 Ⓡ AWM STYLE 1429 20AWG 80℃ 150V VW-1 --- C Ⓡ AWM I A 80℃ 150V FT1 -F- -LF- PC10 LTK				
Applications				
For Internal Wiring of Appliances or Electronic Equipment				
Revisions				
Version	Description	Drawn by	Approved by	Date
0	New document issue	Lisa	Jason	18/05/2015
Construction				
Conductor		Stranded Tinned Copper		
Size(AWG)		20		
Construction(±0.008mm)		26/0.16		
Stranded Dia.(mm)Ref.		0.94		
Insulation Material		XLPVC		
Insulation Color		ANY COLOR		
Ave Thickness(mm)		0.26		
Insulation Dia.(±0.06mm)		1.46		
Remark: <div>8775392 Red 8775395 Blue 8775415 Grey 8775418 Violet 8775389 Black 8775399 White 8775402 Yellow 8775383 Brown 8775409 Green 8775406 Orange</div>				
Characteristics				Customer Approve
Test Item		Standard Value		Seal & Stamp
Test Material		XLPVC(ROHS)		
Insulation DC resistance(MΩ*km)		10		
Vol. Tesr(AC.V.60S) (V)		2000		
Flammability Test		VW-1		
Max.DC Resistance(20℃ Ω/km)		34.6(MAX)		
Signature:				
Date:				