

FEATURES

- Pozidriv head type for improved screwdriver grip
- Pan head design for a flat bearing surface
- A2 stainless steel
- Easily Cleanable
- Meets DIN 7985 Standards

RS PRO, M2 Pan Head, 4mm Stainless Steel Pozidriv A2 304

RS Stock No.: 914-1462



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description


From RS PRO a high-quality pan head machine screw with a versatile Pozidriv recess for a superior grip when tightening. This machine screw has a metric thread and is made from high-quality A2 stainless steel which has strong abrasion resistance and excellent resistance to corrosion.

General Specifications

Head Shape	Pan
Drive Type	Pozidriv
Applications	Food processing and brewing equipment, Domestic appliances, Building fasteners and fixings, Medical equipment, Non-salt water marine applications

Mechanical Specifications

Thread Size (Metric)	M2
Length Metric	min 3.75 max 4.25mm
Material	Stainless Steel
Stainless Steel Type	304 (A2)
Finish	Plain
Thread Pitch	0.4mm
Head Diameter	3.7mm to 4mm
Head Height	1.72mm to 1.48mm
Recess Diameter	1.17mm to 1.42mm
Specification	DIN 7985
DK head Dia	DK head Dia

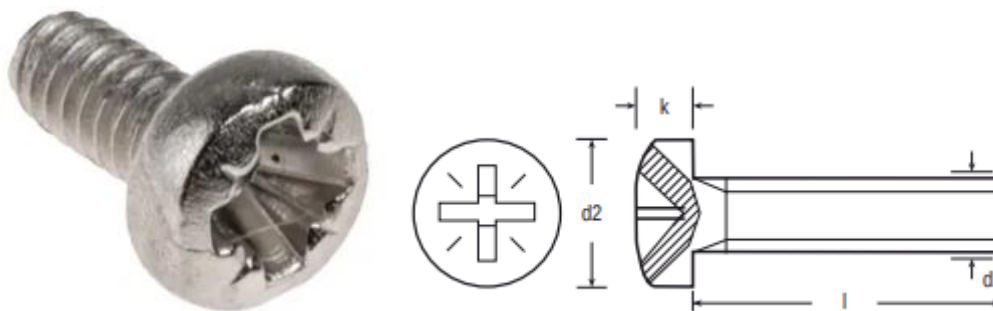

d1	M1.6	M2	M2.5	M3	M3.5	M4	M5	M6	M8
d2	3.20	4.00	5.00	6.00	7.00	8.00	10.00	12.00	16.00
k	1.42	1.72	2.12	2.52	2.82	3.25	3.95	4.75	6.15
Recess no.	0	1	1	1	2	2	2	3	4