



MASTER TL-D 90 De Luxe

MASTER TL-D 90 De Luxe 58W/940 1SL

Low-pressure mercury discharge lamps with a tubular 26 mm envelope

Product data

• General Characteristics

Cap-Base Bulb	G13 [Medium Bi-Pin Fluorescent] T8 [26 mm]
Life to 10% failures EM	12000 hr
Life to 10% fail Preheat EL,3h	17000 hr
Life to 10% fail Nonpreh EL,3h	10000 hr
Life to 50% failures EM	15000 hr
Life to 50% fail Preheat EL,3h	20000 hr
Life to 50% fail Nonpreh EL,3h	12000 hr
LSF EM 2000h Rated, 3h cycle	99 %
LSF EM 4000h Rated, 3h cycle	99 %
LSF EM 6000h Rated, 3h cycle	99 %
LSF EM 8000h Rated, 3h cycle	99 %
LSF EM 12000h Rated,3h cycle	89 %
LSF EM 16000h Rated,3h cycle	33 %
LSF EM 20000h Rated,3h cycle	2 %

• Light Technical Characteristics

Colour Code	940 [CCT of 4000K]
Colour Rendering Index	91 Ra8
Colour Designation	Cool White
Colour Temperature	4000 K

Luminous Flux EM 25°C, Rated	4600 Lm
Luminous Flux EM 25°C, Nominal	4600 Lm
Lum Efficacy Rated EM 25°C	78.6 Lm/W
Average Luminance EM	1.25 cd/cm ²
LLMF EM 2000h Rated	96 %
LLMF EM 4000h Rated	95 %
LLMF EM 6000h Rated	94 %
LLMF EM 8000h Rated	93 %
LLMF EM 12000h Rated	92 %
LLMF EM 16000h Rated	91 %
LLMF EM 20000h Rated	90 %
Design Temperature	25 C
Chromaticity Coordinate X	381 -
Chromaticity Coordinate Y	379 -

• Electrical Characteristics

Lamp Wattage	58 W
Lamp Wattage EM 25°C, Nominal	58 W
Lamp Wattage EM 25°C, Rated	58.5 W
Lamp Voltage EM 25°C	111 V



asimpleswitch.com

PHILIPS

MASTER TL-D 90 De Luxe

Lamp Current EM 0.670 A
25°C
Dimmable yes

• Environmental Characteristics

Energy Efficiency Label (EEL) A
Mercury (Hg) Content 3.0 mg
Energy consumption 68 kWh/1000h


• Product Dimensions

Base Face to Base Face A 1500.0 (max) mm
Insertion Length B 1504.7 (min), 1507.1 (max) mm
Overall Length C 1514.2 (max) mm
Diameter D 28 (max) mm

• Product Data


Order code 888693 25
Full product code 871150088869325
Full product name MASTER TL-D 90 De Luxe 58W/940 1SL
Order product name MASTER TL-D 90 De Luxe 58W/940 1SL/10
Pieces per pack 1
Packing configuration 10
Packs per outerbox 10
Bar code on pack - EAN1 8711500888693
Bar code on outerbox - EAN3 8711500888709
Logistic code(s) - 12NC 928045094081
ILCOS code FD-58/38/1A-E-G13
Net weight per piece 186.000 gr

Dimensional drawing

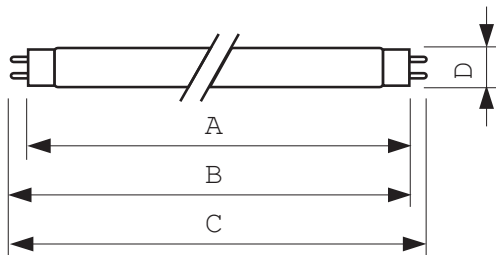



MASTER TL-D 90 De Luxe 58W/940 1SL

Product	A (Max)	B (Min)	B (Max)	C (Max)	D (Max)
TL-D De Luxe 58W/940	1500.0	1504.7	1507.1	1514.2	28

 

G13

Photometric data

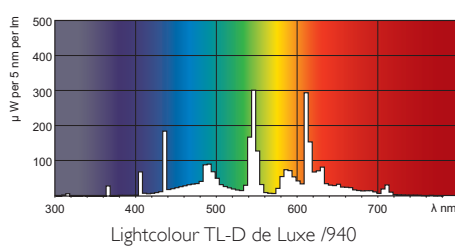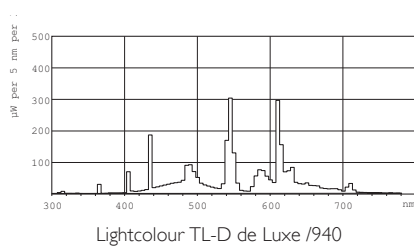



© 2014 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, October 31
data subject to change