




Manual Unlock PV Connector

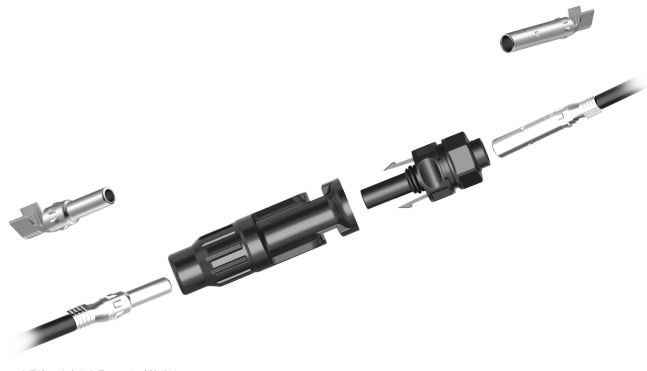


Specification

Applicable Terminal	2.5 mm ²
Rated Current	25 A
Cable Size Range	14 AWG
Rated Voltage	1.5 kVDC
Contact Resistance	300 mOhm
Degree of Protection	IP68
Working Temperature	-40 ~ 105°C
Class of Pollution	Grade III
Flammability	UL94-V0


Drawings

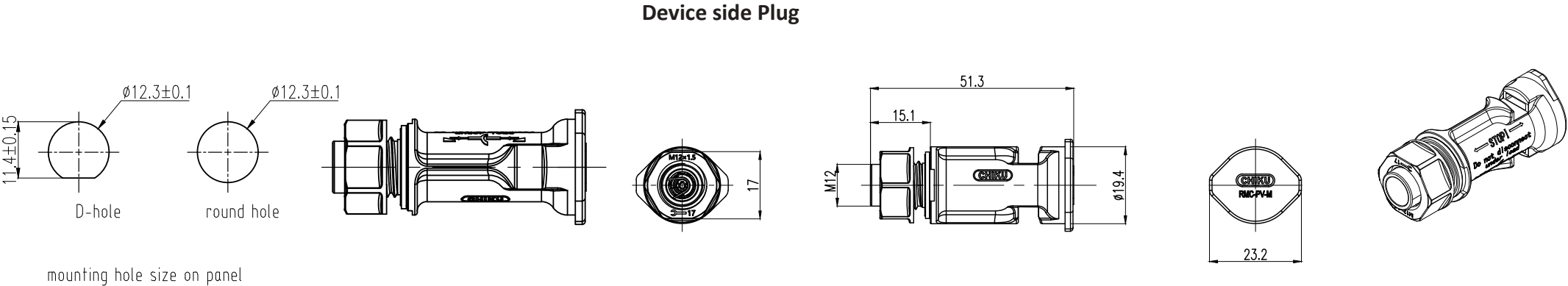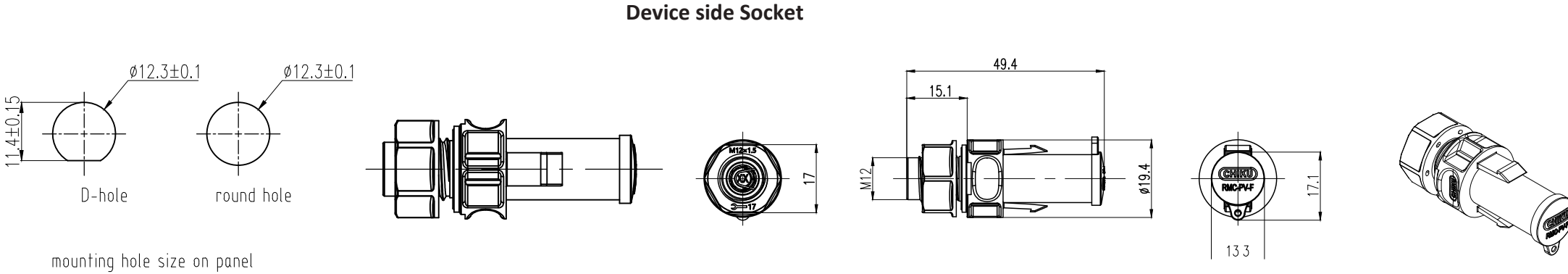

Terminal Socket

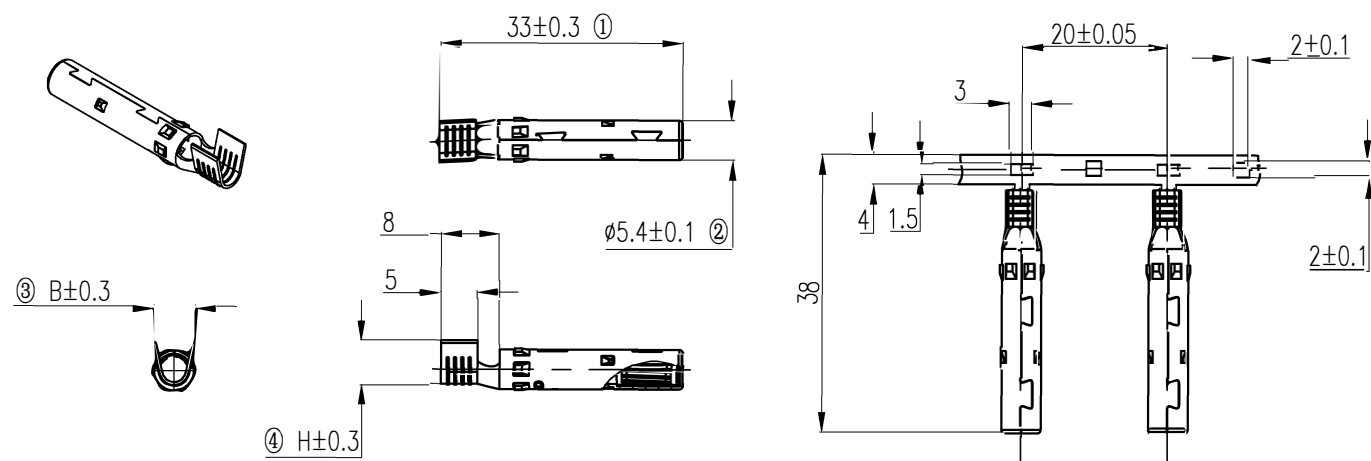

Terminal Plug

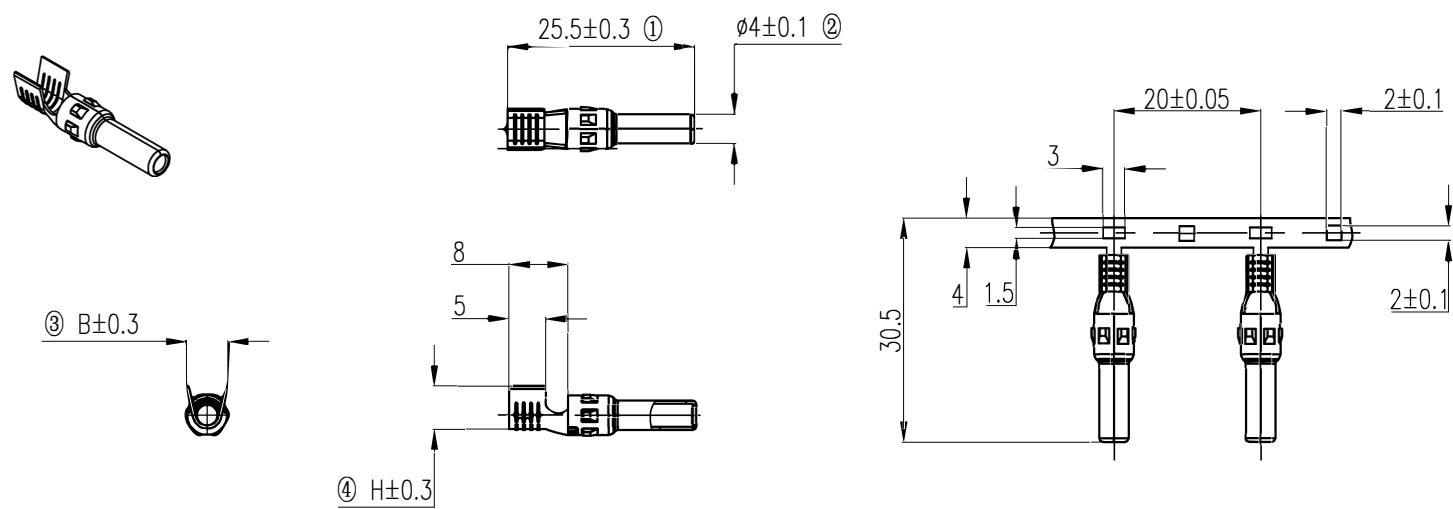

Art. Nr.
RND 205-01574