



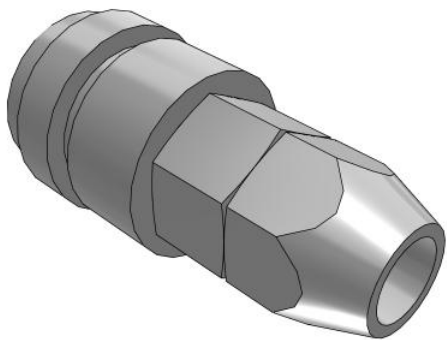

KK*S-*N, S-Couplers, Nut Fitting KK3S-50N

- Nut Fitting.
- Body size: 1/8, 1/4, 1/2.
- Applicable hose O.D.: ø8, ø9, ø10, ø12, ø12.5, ø16.

Body Size	3 (1/8)
Applicable Hose I.D./O.D.	5/8 mm
-	Air, Water
Maximum operating pressure	1.0 MPa
Minimum operating pressure	-100 kPa
Proof pressure	1.5 MPa
Effective Area	20 mm ²
Sealing principle	Electroless nickel plated (copper-free application), With male thread sealant
Weight	0.030 Kg

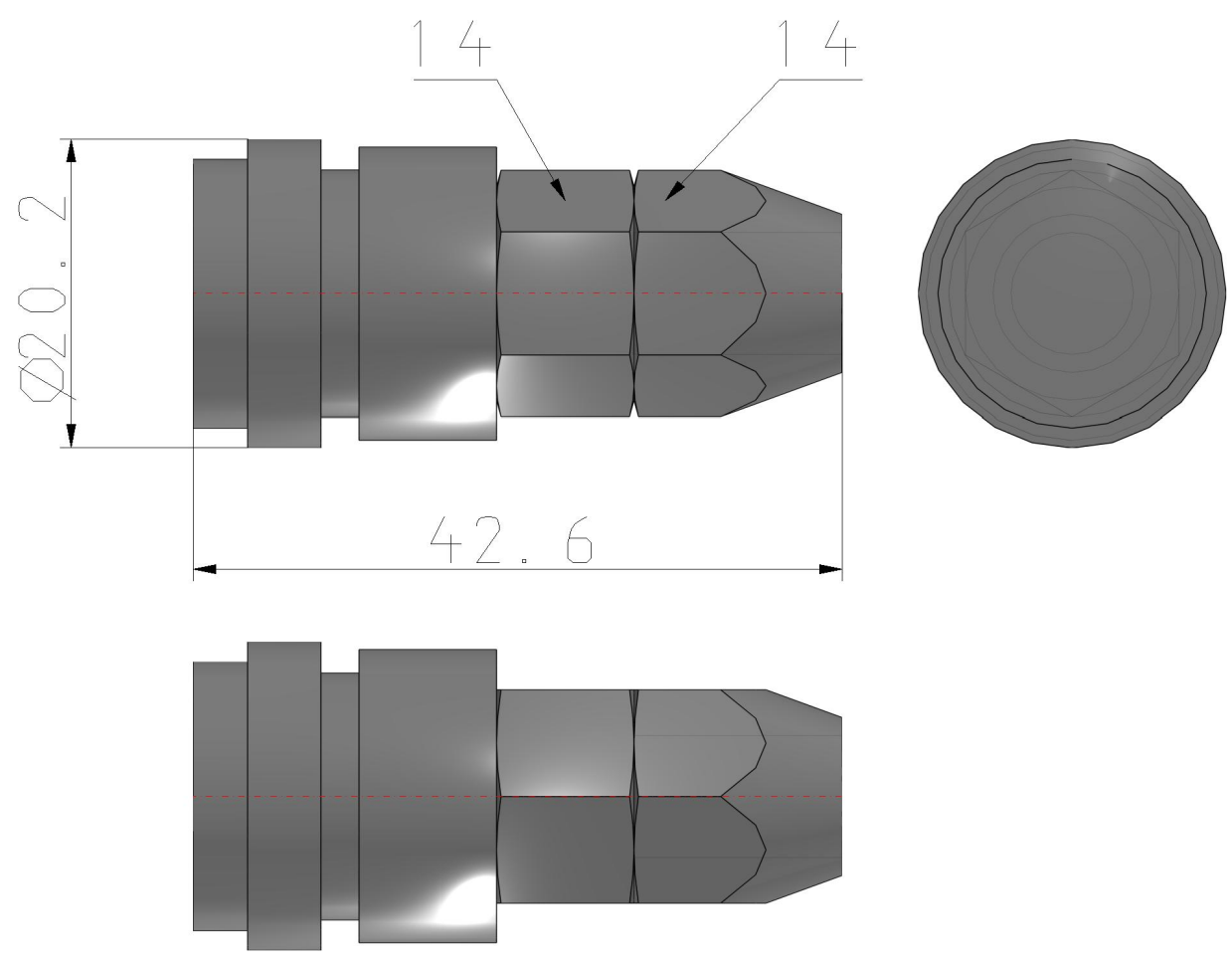

-
-

KK-C_EU.pdf