


### Standard mâle

T° 200°C (maxi 250°C)

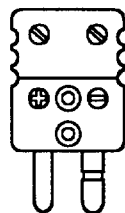

 
- 1065K
- 1065J
- 1065T
- 1065S
- 1065N
- .....

### Thermocouple type

- K
- J
- T
- S
- N

### Standard femelle


T° 200°C (maxi 250°C)



- 1015K
- 1015J
- 1015T
- 1015S
- 1015N
- .....

### Standard mâle Jab In Montage rapide

T° 200°C (maxi 250°C)

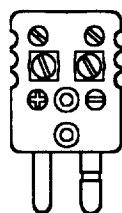


- 1064K
- 1064J
- 1064T
- 1064S
- 1064N
- .....

### Thermocouple type

- K
- J
- T
- S
- N

### Standard femelle Jab In Montage rapide


T° 200°C (maxi 250°C)

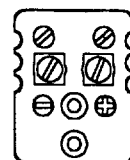

- 1014K
- 1014J
- 1014T
- 1014S
- 1014N
- .....

### Standard mâle Haute T°

T° 420°C (maxi 540°C)

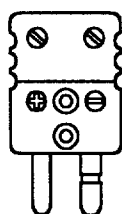


- 1160K
- 1160J
- 1160T
- 1160S
- 1160N
- .....

### Thermocouple type

 - K
- J
- T
- S
- N

### Standard femelle Haute T°


T° 420°C (maxi 540°C)



- 1110K
- 1110J
- 1110T
- 1110S
- 1110N
- .....

### Standard mâle Haute T° Jab In Montage rapide

T° 420°C (maxi 540°C)

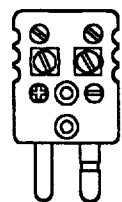


- 1164K  RS3706650
- 1164J
- 1164T
- 1164S  RS3706666
- 1164N
- .....

### Thermocouple type

- K
- J
- T
- S
- N

### Standard femelle Haute T° Jab In Montage rapide

T° 420°C (maxi 540°C)

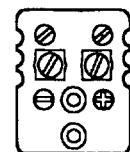

- RS3706672 1114K
- 1114J
- 1114T
- RS3706684 1114S
- 1114N
- .....

FC115-10/98-1