



ENGLISH

Datasheet

# RS PRO SMD Rework Station AC220~240V

## 700W


RS Stock no: 124-4133



### Specifications:

Model Number	124-4133
Plug type	B and C
Primary Application Category	Soldering
Input Voltage	220V ~240V
Output Power	700 W
Nozzle	φ4.3mm / φ7.4mm / φ9.4mm
Maximum Operating Temperature	450 °C
Minimum Operating Temperature	100 °C
Number of Outputs	1
Display Type	LED
Equipment noise	45dB
Air-Volume	120L / min (Max)
Height	170mm
Width	140mm
Depth	170mm
Weight	1.35 kg

## EU B & C type plug

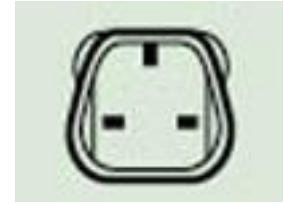

## Accessory:

RS Part no.	Description
137-2237	Replacement hot air gun for 124-4133
137-2236	Replacement nozzles (3 sizes) $\phi$ 4.3mm / $\phi$ 7.4mm / $\phi$ 9.4mm for 124-4133

## Features:

Hot air SMD rework station with heat gun holder

Microprocessor temperature controlled with closed circuit sensor design, provide high power and quick warm up times.

Adjustable air flow, air volume and temperature control

Auto-sleep and work mode

Temperature display

Brushless motor design, quiet operation, equipment noise less than 45 dB

Automatic cool-off process to prolong the life of heating element

The wires are AWG 20 (0.5MM<sup>2</sup>) UL certified

Metal case design adds to durability

Supplied with 3 nozzles

Complies with CE standard. Conform to RoHS.