





English	Français	Deutsch	Italiano	Español
Body: Stainless steel* Natural	Corps: Inox* Brut	Hülse: Edelstahl* Unbehandelt	Corpo: Acciaio inox* Nessuna finitura	Cuerpo: Acero inoxidable* Natural
Stem: Stainless steel Natural	Tige: Inox Brut	Dorn: Edelstahl Unbehandelt	Gambo: Acciaio inox Nessuna finitura	Vástago: Acero inoxidable Natural


\*: 300 Series

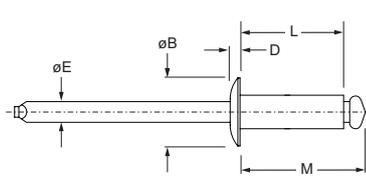

 
**SSD ■ SSBS**  
Dome head  
Tête bombée / Flachrundkopf /  
Testa tonda / Cabeza alomada

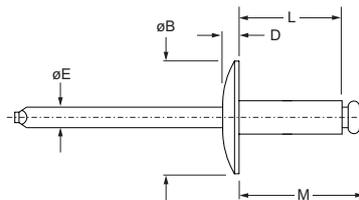

**SSD ■ SSBS LF**  
Large flange  
Tête large / Flachrundkopf, extragroß /  
Testa larga / Cabeza ala ancha

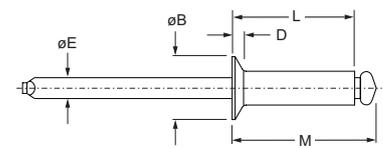

**SSK ■ SSBS**  
Countersunk  
Tête fraisée / Senkkopf /  
Testa svasata / Cabeza avellanada

Ø nom.					L ref.	M ref.	ØE ref.	SSD ■ SSBS			SSD ■ SSBS LF			SSK ■ SSBS				
	min.	max.	min.	max.				ØB max.	D max.	Part No. ■	ØB max.	D max.	Part No. ■	ØB max.	D max.	Part No. ■		
3.2 (1/8")	0.8	1.6	3.28	3.38	4.8	7.8	1.9	6.7	1.1	41	10.0	1.2	44	6.0	1.3	44		
	1.6	3.2			6.4 <sup>1)</sup>	9.4				42							42	43
	3.2	4.8			8.0	11.0				43								
	4.8	6.4			9.5	12.6				44								
	6.4	7.9			11.1	14.2				45								
	7.9	9.5			12.7	15.7				46								
	9.5	12.7			15.9	18.9				48								
4.0 (5/32")	1.6	3.2	4.06	4.17	7.0	10.5	2.4	8.4	1.2	52								
	3.2	4.8			8.6	12.1				53								
	4.8	6.4			10.2	13.7				54								
	6.4	9.5			13.3	16.9				56								
4.8 (3/16")	1.6	3.2	4.88	4.98	7.6	11.7	2.9	10.0	1.4	62	16.6	2.2	68	9.3	1.8	68		
	3.2	6.4			10.8	14.9				64							64	
	6.4	9.5			14.0	18.0				66								
	9.5	12.7			17.2	21.2				68								
	12.7	15.9			20.3	24.4				610								
	22.3	25.4			29.7	33.9				616								

all dimensions in mm / en millimètre / alle Maße in mm / in millimetri / en milímetros  
1) SSK 42 SSBS: 7.0

Ø nom.	 kN <sup>2)</sup>	 kN <sup>2)</sup>
3.2 (1/8")	2.45	3.12
4.0 (5/32")	4.01	5.03
4.8 (3/16")	4.45	6.12

2) typical values / valeurs moyennes / typische Werte / Valori tipici / valores típicos