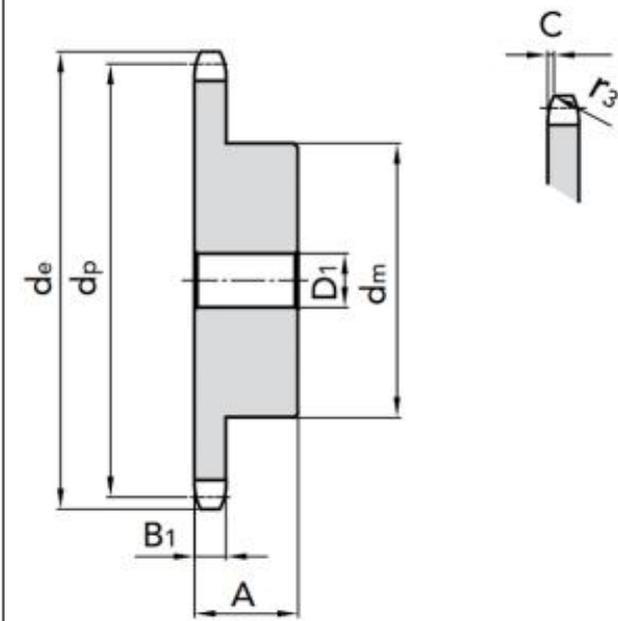


10112030

1/2in x 5/16in - Chain sprockets ISO

2D Technical Drawing

Dynamic 3D View

Technical Specifications

Number of teeth (T)	30
de (DE) mm	125.99
dp (DP) mm	121.50
Part number (CODE)	10112030
dm (DM) mm	80
D1 (D1) mm	16
A (A) mm	30
Tooth radius r3 (R3) mm	13
Radius width C (C) mm	1.3
Sprockets tooth width B1 (B1) mm	7.2
Weight (WEIGHT) kg	1.46
Material (MAT)	STEEL C 45