



Sub-Miniature Slide Switch

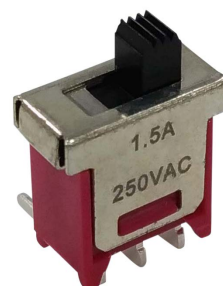

Specification

Contact Material	Copper Alloy, Silver Plated
Terminal Material	Copper Alloy, Silver Plated
Contact Resistance	20 mOhm
Contact Configuration	SPDT
Contact Rating	3 A with Resistive Load @ 125 VAC or 28 VDC 1.5 A with Resistive Load @ 250 VAC
Insulation Resistance	1000 MOhm
Dielectric Strength	1500 V RMS
Electrical Life	30000 Make and Break Cycles at Full Load
Operating Temperature Min.	-30 °C
Operating Temperature Max.	85 °C
Switch Function	On-On
Actuator Height	3 mm
Actuator Colour	Black
Termination Type	PC, Through-Hole, Right Angle
Seal	Epoxy

Drawing

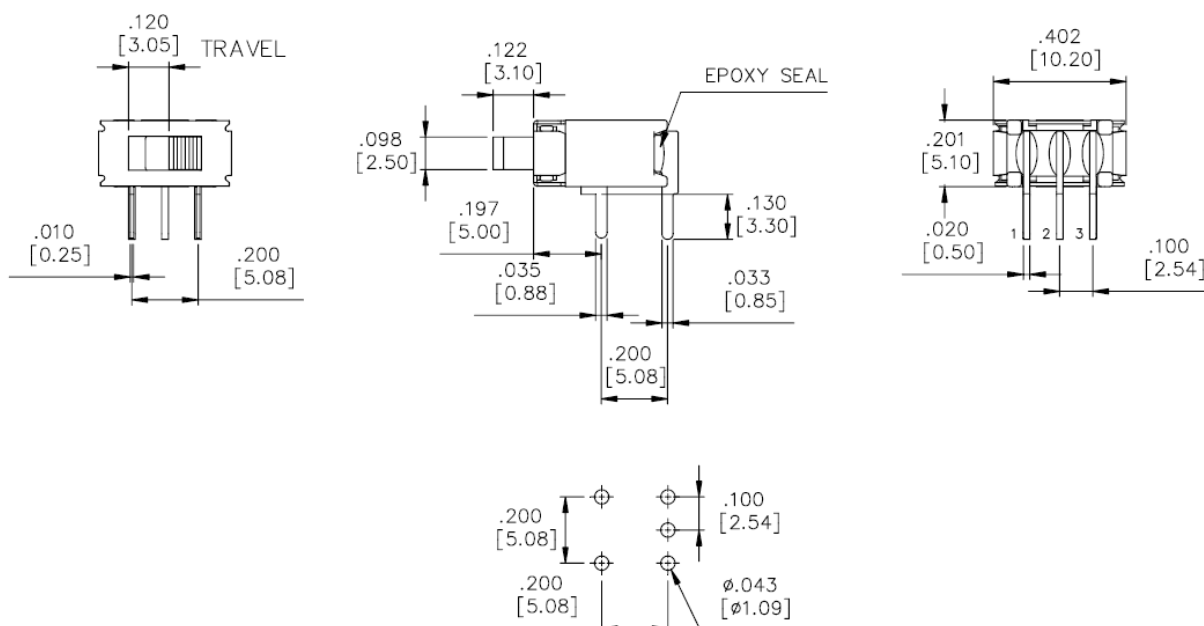

Art. Nr.
RND 210-00594