


KEMET Part Number: PHBC20-1R7A0054V
(UALP201R7A0054)

KEMET, PHBC, AC Line Filters, Normal Mode, 54 uH, 20%

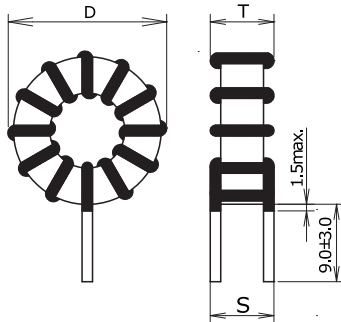

Dimensions

D	41.2mm MAX
T	19.5mm MAX
LL	9mm +/-3mm
S	14mm NOM

Packaging Specifications

Packaging:	Tray
Packaging Quantity:	80
Weight:	66 g

General Information

Series:	PHBC
Style:	Through-Hole
Features:	Switching Power Supply Outlet, DC-DC Converter, Phase Compensation, Noise Solution
RoHS:	Yes
Miscellaneous:	35 (K) Temperature Rise Max.

Specifications

Inductance:	54 uH (0.1 MHz)
Inductance Tolerance:	20%
Current:	12 A
Temperature Range:	-40/+125°C
DC Resistance:	11.5 mOhms