




GSM Mini Quad Band Antennas

Compact PCB Antennas for GSM Cellular applications where high performance is required from a small size.

GSMQB Antenna

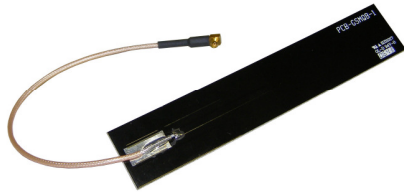

GSMMQB Antenna



- Higher Performance PCB Antenna
- 850/900/1800/1900MHz
- Active gain: +1dB
- Linear Polarisation
- 15cm RG178 Connecting Lead
- VSWR ≤ 2.0
- Groundplane Independent
- Available with SMA/ufl or MMCX Fixing
- Power Rating 10W
- Operates from 2.7—5.5V

- Miniature Sized PCB Antenna
- 850/900/1800/1900MHz
- VSWR ≤ 3.0
- Omni Directional
- Horizontal Polarisation
- 10cm RG174 Connecting Lead
- 50 Ω Impedance
- Power Rating 10W
- Supplied with ufl Connector
- Alternative connectors available on request

Part Numbers

	Length	Width	Max Height	Cable Length	Connector
ANT-GSMQB-MMCX	110mm	20mm	5mm	100mm	MMCX 90°
ANT-GSMQB-SMA	110mm	20mm	5mm	100mm	SMA
ANT-GSMMQB-UFL	34mm	7mm	0.8mm	100mm	ufl

R F Solutions Ltd., Lewes, E. Sussex. BN8 6JL. England.

Email : sales@rfsolutions.co.uk <http://www.rfsolutions.co.uk>

Tel: +44 (0)1273 898 000 Fax: +44 (0)1273 480 661