


Blue Elastic Rubber Trolley Wheel 200mm, ball bearings, 400kg

Elastic Rubber-tyred wheel

PRODUCT

Article number **571-511-200B20**

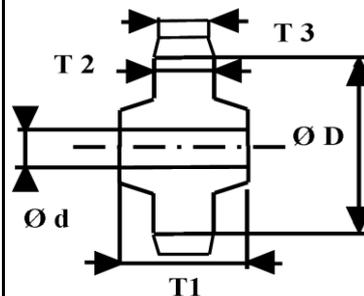

Product Details

Wheel Rim : very thick black polyamide.
 Tyre : solid, blue bonded elastic rubber tyre, non marking.
 Hub : symmetrical, two ball bearings.

Specifications

Wheel Diameter - ØD ± 1%	200 mm
Hub Type	two ball bearings
Hub Length T1	60 mm ±1
Width of Tread T2	45 mm ±1
Width of Tread-on floor T3	45 mm ±1
Axle Hole Ø d	Ø 20 mm
Hardness of tread A ±4	A 70 Shore
Load capacity	400 Kg
Temperature	-20 / +60 °C
Weight	1,15 Kg

TECHNICAL DATA

Applications :

Sensitive materials handling on uneven surfaces.
 Resilient with a low starting effort.
 Does not leave scratches or other marks on surfaces.
 Reduce schok and vibration.
 Quiet in use and high wear resistance.
 Towable by mechanized vehicle.
 Suitable for industrial floors and also all interior floors.