

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0451361010](#)
Status: **Active**
Overview: [Mega-Fit Power Connectors](#)
Description: Mega-Fit-to-Mega-Fit Off-the-Shelf (OTS) Cable Assembly, Dual Row, 1.0m Length, Matte Tin Plated, 10 Circuits, Black

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	45136
Application	Power
Assembly Configuration	Dual Ended Connectors
Connector to Connector	Mega-Fit-to-Mega-Fit
Overview	Mega-Fit Power Connectors
Product Name	Mega-Fit OTS
UPC	191128777933

Physical

Cable Length	1.0m
Circuits (Loaded)	10
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Matte Tin
Material - Plating Termination	Matte Tin
Material - Resin	Nylon
Packaging Type	Bag
Pitch - Mating Interface	5.70mm
Plating min - Mating	1.524µm
Plating min - Termination	1.524µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	4.35mm
Wire Size AWG	12
Wire/Cable Type	UL 1015


Electrical

Current - Maximum per Contact	23.0A
Voltage - Maximum	600V

Material Info

Reference - Drawing Numbers

Sales Drawing	451361001-000
---------------	---------------

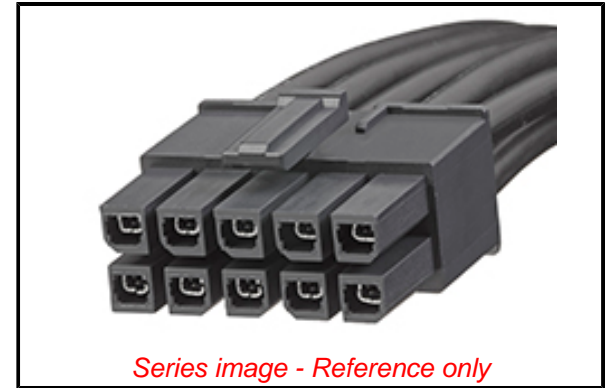

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
------------	--------------

ELV	Not Reviewed
-----	--------------

RoHS Phthalates	Not Reviewed
-----------------	--------------

Search Parts in this Series

[45136](#) Series

Mates With

Mega-Fit Header [76825](#) , [76829](#) , [172064](#) , [172065](#)