

Deep groove ball bearings, single row, unsealed

Product information



Tolerances , see also text

Radial internal clearance , see also text

Recommended fits

Shaft and housing tolerances

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			C	C_0	kN	r/min	kg	-	* - SKF Explorer bearing
85	150	28	87,1	64	2,5	9000	1,80	6217 *	

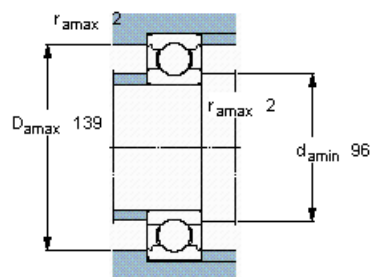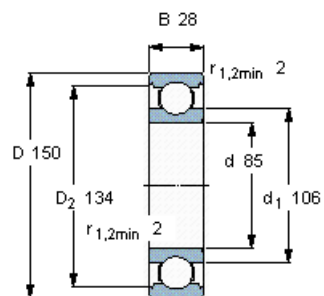

Calculation factors

k_f 0,025

f_0 15