


KEMET Part Number: FF1(200)-240X240T0800
(UFSFF1020AT080)

KEMET, FF1, Flex Suppressors, Noise Suppression

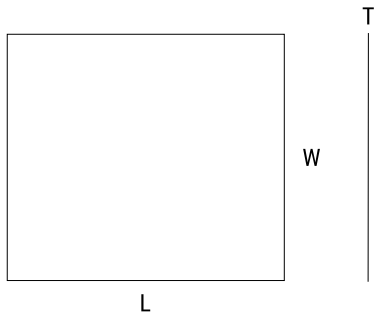

General Information	
Series:	FF1
Style:	Sheet
Description:	Flex Suppressor Flame Retardant Type
Features:	Flame Retardant Type
RoHS:	Yes
Qualifications:	UL94 V-0, UL File No.E176124, AEC-Q200
Environment:	RoHS Compliant, Halogen Free, PVC Free, Lead Free

Dimensions	
Sheet Size	240x240mm
L	240mm NOM
W	240mm NOM
T	0.2mm NOM

Packaging Specifications	
Tape Description:	Without PET Tape (Txx00)
Tape Thickness:	0.03mm
Weight:	36.59 g

Specifications	
Temperature Range:	-40/+125C
Magnetic Permeability:	100 u At 3MHz
Effective Frequency:	10 GHz MAX
Resistance:	1 MOhms MIN
Specific Gravity:	3.1 Atm TYP
Conductivity:	1.8 W/m K
Tensile Strength:	10.8 MPa MIN