


SK 5,08/3,8 DN - Marker card

1965458

<https://www.phoenixcontact.com/gb/products/1965458>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

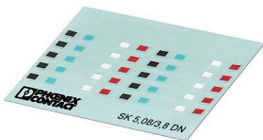

Marker card, Card, white, labeled: without print, mounting type: adhesive, for terminal block width: 5.08 mm

Commercial data

Item number	1965458
Packing unit	5 pc
Minimum order quantity	5 pc
Sales key	BG2123
Product key	BG2123
Catalog page	Page 25 (PC-2005)
GTIN	4017918927271
Weight per piece (including packing)	0.722 g
Weight per piece (excluding packing)	0.446 g
Customs tariff number	39199080
Country of origin	DE

SK 5,08/3,8 DN - Marker card



1965458

<https://www.phoenixcontact.com/gb/products/1965458>

Technical data

Product properties

Product type	Labeled terminal marker
Number of positions	5
Pitch	5.08 mm
Type	Label

Marking

Number of marker strips	12
Printing	without print
Identification technology	Thermal transfer for rolls

Mounting

Mounting type	adhesive
---------------	----------

Material specifications

Color	white (RAL 9010)
Material	Polyester
Base element material	Polyester
Components	free from silicone and halogen

Environmental and real-life conditions

Test for substances that would hinder coating with paint or varnish

Result	Test passed
--------	-------------

UV resistance

Specification	ISO 4892-2:2013-03 (following)
Result	Test passed
Test duration	96 h

Wipe resistance of inscriptions

Specification	DIN EN 61010-1 (VDE 0411-1):2011-07
	DIN EN 62208 (VDE 0660-511):2012-06 (in parts)
Isopropyl [CAS No. 67-63-0]	Test passed
n-Hexane [CAS No. 110-54-3]	Test passed
Water + Petroleum ether [CAS No. 64742-82-1]	Test passed

Testing in a condensation changing climate in the presence of sulfur dioxide

Specification	DIN 50018:2013-05
Result	Test passed
Climate level	AHT 1.0 S
Cycles	2

SK 5,08/3,8 DN - Marker card



1965458

<https://www.phoenixcontact.com/gb/products/1965458>

Salt spray test

Specification	DIN EN 60068-2-11:2000-02
Result	Test passed
Test duration	96 h

Ambient conditions

Ambient temperature (operation)	-40 °C ... 150 °C
Recommended ambient temperature (storage/transport)	23 °C
Recommended humidity (storage/transport)	50 %
Shelf life	12 months

Dimensions

Width	5.08 mm
Height	3.8 mm
Pitch	5.08 mm

Standards and regulations

Wipe resistance	DIN EN 61010-1 (VDE 0411-1)
-----------------	-----------------------------

SK 5,08/3,8 DN - Marker card

1965458

<https://www.phoenixcontact.com/gb/products/1965458>



Classifications

ECLASS

ECLASS-11.0	27281101
ECLASS-12.0	27281101
ECLASS-13.0	27281101

ETIM

ETIM 9.0	EC000761
----------	----------

UNSPSC

UNSPSC 21.0	39131500
-------------	----------

SK 5,08/3,8 DN - Marker card



1965458

<https://www.phoenixcontact.com/gb/products/1965458>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT Ltd
Halesfield 13, Telford
Shropshire, TF7 4PG
01952 681700
info@phoenixcontact.co.uk