


NSYMR128

Monobloc perforated plates H1200xW800mm
with universal perforations 11x26mm

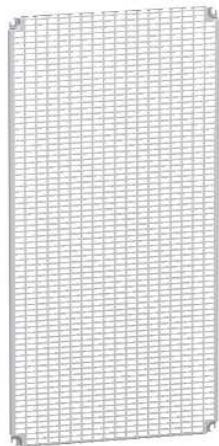

Main

Commercial Status	Commercialised
Range	Mounting accessories
Category	Mounting Plate
Application	Multi-purpose
Mounting location	Step slide Direct fixing on backstuds
Mounting plate description	Telequick perforated
Product compatibility	S3D, CRN, S3X, PLM, S57 enclosures
Quantity per set	Set of 1
Material	Steel
Surface finish	Zinc coated

Complementary

Fixing mode	By fixing element Screwed on backstuds - screw type M8
Height	1145 mm
Width	751 mm
Depth	15 mm
Thickness	2 mm
Product weight	6.4 kg
Number of slots	1800
Variant particularity	Installation in rear of enclosure
Cut-out dimensions	11 x 26 mm

Offer Sustainability

Sustainable offer status	Green Premium product
RoHS	Compliant - since 0940 - Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold
Product environmental profile	Available
Product end of life instructions	Need no specific recycling operations

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.