

Datasheet

## RS Pro E10 Filament Indicator Lamp, Clear, 48 V, 100 mA, 1000h

RS Stock No: **106-335**



### Product Details

RS Pro E10 filament indicator lamp comes with clear lens. It has a voltage rating of 48 V and current rating of 100 mA. The lamp has 1000 h life. The MES tungsten halogen filament lamp is suitable for use with many popular torches and hand lamps.

### Features and Benefits

- Voltage rating of 48 V
- Current rating of 100 mA
- 1000 hours lifetime




**Specifications:**

|                |        |
|----------------|--------|
| Current Rating | 100 mA |
| Diameter       | 10 mm  |
| Lamp Base      | E10    |
| Lamp Size      | T3 1/4 |
| Length         | 28 mm  |
| Lens Colour    | Clear  |
| Life Hours     | 1000 h |
| Luminosity     | 38 lm  |
| Voltage Rating | 48 V   |

RS Stock No.

106335

*DRAWING - I*

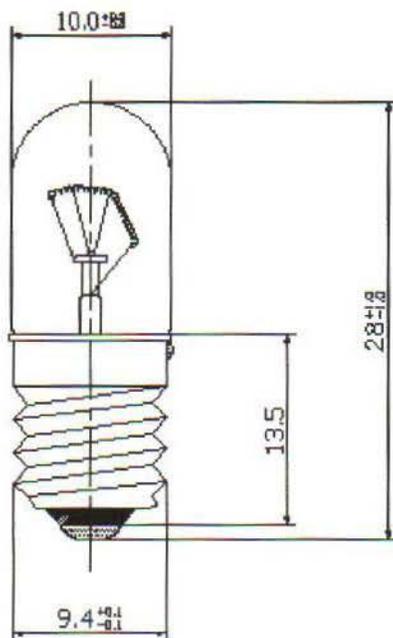

Unit : mm

|                           |               |              |
|---------------------------|---------------|--------------|
| 1. Structure              | Bulb Type     | T3 1/4 Clear |
|                           | Bulb Diameter | Ø10.0Max.    |
|                           | Length        | 28.0Max      |
|                           | Base Type     | E10          |
| 2. Design Characteristics | Voltage       | 48V          |
|                           | Amperage      | 100mA± 10%   |
|                           | Filament Type | Vacuum type  |
|                           | Luminous Flux | 38Lm± 20%    |
|                           | Life Hours    | 1,000Hrs     |