




Datasheet

ENGLISH

RS Pro Proximity Reed Switch Magnet - M8 x 0.75 mm

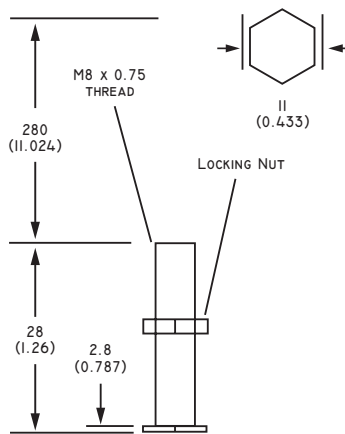

Drawings not to scale
All dimensions in mm (inches) nominal

APPLICATIONS

- Position and limit sensing.
- Linear actuators.
- Door and window security.

OPTIONS

- Case material.
- Sensitivity / Switching distance
- Thread Size.

✓ RoHS Compliant

SPECIFICATIONS

Contact Form	Normally Open
Style	Threaded (M8 Thread)
Switching Capacity Switching	10 W/VA Max.
Voltage	200 VDC/AC Max.
Switching Current	0.5 A. Max.
Contact Resistance Switching	200 mOhms. Max.
Distance Operating	10 mm Min.
Temperature Range Case	-20°C +85°C
Material	Brass